


FPCM-APSC/PLC-1M

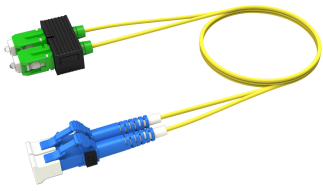

Fiber Optic Patch Cord, 2.0 mm simplex, standard singlemode, SC/APC-LC /UPC, 1 m, yellow

Product Classification

Regional Availability	Latin America North America
Product Type	Fiber patch cord, duplex
Product Series	FPCM

General Specifications

Connector A, quantity	2
Color, boot A	Blue
Color, connector A	Blue
Connector B, quantity	2
Color, boot B	Green
Color, connector B	Green
Interface, Connector A	LC/UPC
Interface, Connector B	SC/APC
Jacket Color	Yellow
Total Fibers, quantity	2

Dimensions

Cord Length	1 m 3.281 ft
Diameter Over Jacket	2 mm 0.079 in

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	OS1
Insertion Loss, maximum, connector A	0.3 dB
Insertion Loss, maximum, connector B	0.35 dB
Return Loss, minimum, connector A	55 dB
Return Loss, minimum, connector B	55 dB

FPCM-APSC/PLC-1M

Environmental Specifications

Environmental Space Plenum

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

