

TFAM18/21P-34



ION®-B Series Medium Power Remote Unit for GSM 1800 and UMTS

OBSOLETE

Product Classification

Product Type Remote unit

Product Brand ION®-B


 
General Specifications

Note Detailed Product Specifications are available. Please contact your local CommScope representative.

Power Type Medium

Dimension Drawing

TFAM18/21P-34

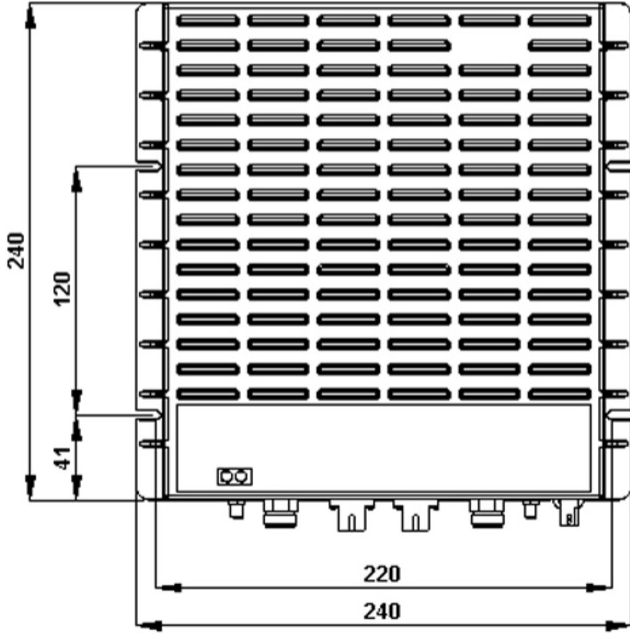

Electrical Specifications

Impedance	50 ohm
License Band	GSM 1800 UMTS
Voltage Range	-60 to -36 Vdc

Electrical Specifications, Rx (Uplink)

Operating Frequency Band	1710 – 1785 MHz (GSM 1800) 1920 – 1980 MHz (UMTS)
---------------------------------	---

Electrical Specifications, Tx (Downlink)

Operating Frequency Band	1805 – 1880 MHz (DCS 1800) 2110 – 2170 MHz (UMTS)
---------------------------------	---

Regulatory Compliance/Certifications

TFAM18/21P-34

Agency

CHINA-ROHS

ISO 9001:2015

REACH-SVHC

ROHS

Classification

Above maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant/Exempted



Included Products

TPSN3/32-80 – Power Supply Adapter ION®-B Series Remote Units, 80 W