


F4XLCLCAS

Base Product

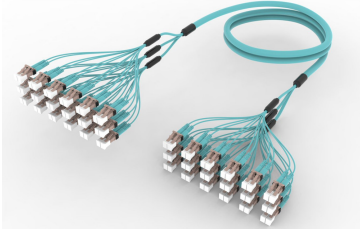

OM4 LC/UPC to LC/UPC 32-Fiber InstaPATCH® 360 Ruggedized Fanout Cable, Low Smoke Zero Halogen, B2ca

Product Classification

Regional Availability	Europe Middle East/Africa
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration Not available in the United States or Canada

General Specifications

Color, boot A	Aqua
Color, connector A	Beige
Color, boot B	Aqua
Color, connector B	Beige
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Jacket Color	Aqua
Fibers per Subunit, quantity	8
Total Fibers, quantity	32

Dimensions

Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	7 – 999

Ordering Tree

F4XLCLCAS



Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode
Fiber Type OM4, LazrSPEED®
Insertion Loss, maximum, connector A 0.24 dB
Insertion Loss, maximum, connector B 0.24 dB
Return Loss, minimum, connector A 27 dB
Return Loss, minimum, connector B 27 dB

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)
EN50575 CPR Cable EuroClass Fire Performance B2ca
Environmental Space Indoor | Low Smoke Zero Halogen (LSZH)

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

F4XLCLCAS

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

