


# 760060871 | VP360-HCM-Kit-37

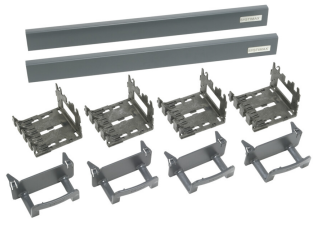

GigaSPEED X10D® VisiPatch® 360 Horizontal Cable Management Kit, 37 In.

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	SYSTIMAX®
<b>Product Type</b>	Cable management hardware
<b>Product Brand</b>	VisiPatch®

## General Specifications

<b>Product Design</b>	VisiPatch® 360
<b>ANSI/TIA Category</b>	6A

## Dimensions

<b>Width</b>	939.8 mm   37 in
<b>Depth</b>	299.72 mm   11.8 in

## Environmental Specifications

<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
<b>Safety Standard</b>	Austel   CE   UL   cUL

## Packaging and Weights

<b>Included</b>	Four back panels (128 pair)   Four horizontal CM troughs   Two horizontal trough covers
<b>Packaging quantity</b>	1

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant

# 760060871 | VP360-HCM-Kit-37

---

UK-ROHS

Compliant

