


7801363 | SFP+, 10GBase CWDM-570, 40km

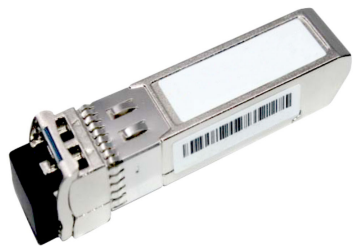

Small form factor pluggable+ Module, 10G BASE, CWDM, Singlemode

Product Classification

Product Type Optical module

General Specifications

Input Connector Interface LC

Note Detailed Product Specifications are available. Please contact your local CommScope representative.

Dimensions

Height 12 mm | 0.472 in

Width 14 mm | 0.551 in

Depth 57 mm | 2.244 in

Optical Specifications

Fiber Type 9/125 μm , singlemode

Wavelength 1571 nm

Environmental Specifications

Operating Temperature 0 °C to +70 °C (+32 °F to +158 °F)