

T-2-UW-NM



Termination Load, 0–6000 MHz

OBSOLETE

This product was discontinued on: November 15, 2022

Replaced By:

T-2-UW-43-M

Termination Load, 0–6000 MHz

Product Classification

Regional Availability Asia | Australia/New Zealand | EMEA | Latin America | North America

Product Type Termination Load

General Specifications

Device Type Termination Load

Application Indoor/Outdoor

Color Black

Inner Contact Plating Silver

Interface N Male

Outer Contact Plating Trimetal

Dimensions

Length 41 mm | 1.614 in

Diameter, maximum 20 mm | 0.787 in

Electrical Specifications

Average Power at Temperature 1.7 W @ 60 °C

Average Power, maximum 2 W


Impedance 50 ohm

Operating Frequency Band 0 – 6000 MHz

VSWR 1.15

T-2-UW-NM

Derating Curve

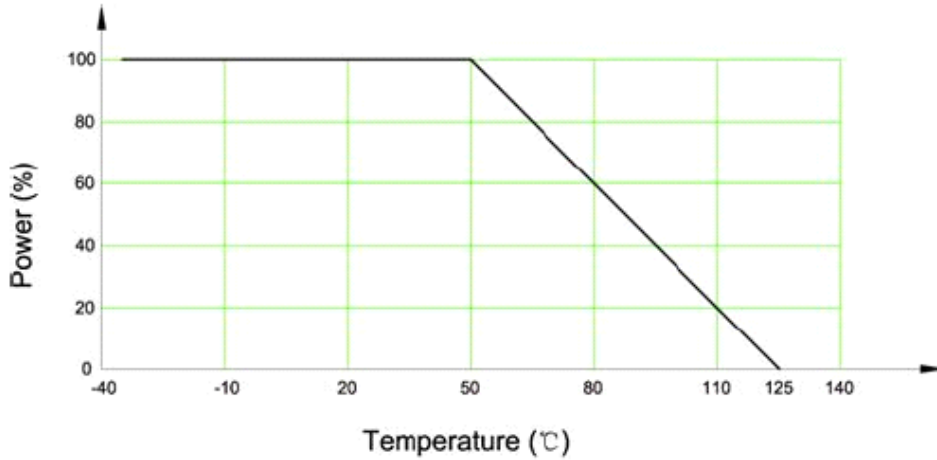

Environmental Specifications

Operating Temperature	-35 °C to +50 °C (-31 °F to +122 °F)
Relative Humidity	Up to 100%
Ingress Protection Test Method	IEC 60529:2001, IP65

Packaging and Weights

Height, packed	68 mm 2.677 in
Width, packed	53 mm 2.087 in
Length, packed	580 mm 22.835 in
Weight, gross	0.06 kg 0.132 lb
Weight, net	0.04 kg 0.088 lb

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

