



COWO Customer Wall Outlet, 1 SC/UPC port, 1 pigtail

- Allows easy and unobtrusive termination of fiber optic cables in an office, home or communications room
- Very flat design, mounts on a standard flush mount electrical outlet
- Possibility to invert the adapter in the holder to prevent disconnection when pulling the patch cords

Product Classification

| | |
|------------------------------|-------------------|
| Regional Availability | EMEA |
| Product Type | Fiber wall outlet |
| Product Series | COWO |


General Specifications

| | |
|-----------------------------------|------------------------|
| Color | White |
| Cover Type | Hinged with latches |
| Interface Type | SC/UPC |
| Lock Type | Lead-wire seal Screw |
| Mounting | Wall mount |
| Splices Included, quantity | 1 |
| Total Ports, quantity | 1 |

Dimensions

| | |
|---------------|----------------------|
| Height | 115.062 mm 4.53 in |
| Width | 80.01 mm 3.15 in |
| Depth | 24.384 mm 0.96 in |

Outline Drawing

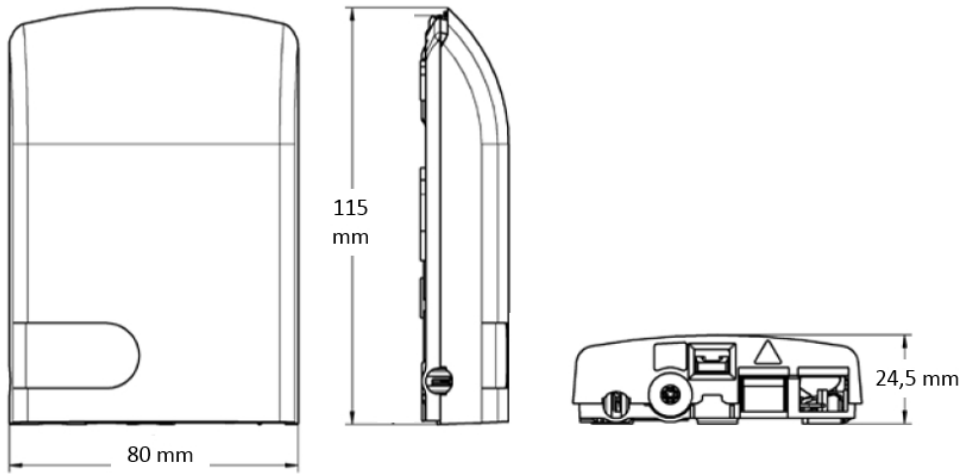

Material Specifications

Material Type LSZH thermoplastic

Optical Specifications

Fiber Mode Singlemode

Environmental Specifications

Operating Temperature -40 °C to +70 °C (-40 °F to +158 °F)

Environmental Space Indoor

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

| Agency | Classification |
|------------|---|
| CHINA-ROHS | Below maximum concentration value |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant |
| UK-ROHS | Compliant |



Included Products

- CY7021-000
COWO-NN00 – COWO Customer Wall Outlet, empty, for holding up to 2 adapters