


FGS-HNTR-F-16MM

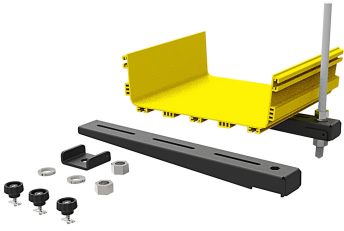

FiberGuide® New Threaded Rod Bracket Kit, 16mm for 4x12in System

Product Classification

| | |
|-------------------------------|---|
| Regional Availability | Asia Australia/New Zealand EMEA Latin America North America |
| Portfolio | CommScope® |
| Product Type | Support mounting kit |
| Product Brand | FiberGuide® |
| Product Series | FGS |
| Minimum Order Quantity | 10 |

General Specifications

| | |
|----------------------------------|--------------|
| Color | Black |
| Orientation | Horizontal |
| Section Type | Bracket |
| Bracket Type | Cantilever |
| Bracket Installation Type | New |
| Attachment Type | Threaded rod |

Dimensions

| | |
|--------------------------|--------------------------------|
| Height | 31.75 mm 1.25 in |
| Width | 50.8 mm 2 in |
| Length | 419.1 mm 16.5 in |
| Thread Size | 16 mm |
| System Dimensions | 102 mm x 305 mm (4 in x 12 in) |

Ordering Tree

FGS-HNTR-F-16MM

FGS - HNTR - ⁹F - ¹⁰5/8

For Section Size

| | | |
|---|-------|--------------------|
| 9 | empty | 4 x 4 in, 4 x 6 in |
| | F | 4 x 12 in |

For Threaded Rod Size

| | | |
|----|--------|------------------|
| 10 | 1/2 | 1/2 in |
| | 12MM | 12 mm |
| | 14MM | 14 mm |
| | 16MM | 16 mm |
| | 3/8 | 3/8 in |
| | 5/8 | 5/8 in |
| | 5/8-A | 5/8 in, modified |
| | 5/8-S | 5/8 in, short |
| | 5/8-XA | 5/8 in, x-aisle |

Material Specifications

Material Type Steel

Packaging and Weights

Included Hardware

Packaging quantity 1

Regulatory Compliance/Certifications

| Agency | Classification |
|------------|---|
| CHINA-ROHS | Below maximum concentration value |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant |
| UK-ROHS | Compliant |

