


CZ8588-000 | OCC1P-20400-NNNQNF

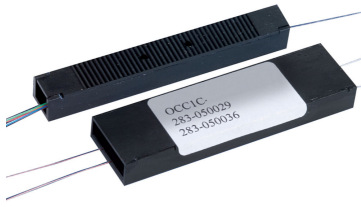

OCC1P Wideband Splitter, planar, singlemode, 2x4, symmetrical split ratio, 0,250 mm cable, field installable

Product Classification

Regional Availability	EMEA Latin America North America
Product Type	Splitter component
Product Series	OCC1P

General Specifications

Device Type	Component, rectangular
Functionality	Splitting
Technology Type	Planar lightwave circuit (PLC)
Application	For use in FOSS closures
Circuits, quantity	1
Distribution Type	2 x 4 splitter
Interface, Input	Stub tail
Interface, Output	Stub tail
Split Ratio	Symmetrical
Splitter, quantity	1

Dimensions

Pigtail Length, Input	2.5 m 8.202 ft
Pigtail Length, Output	2.5 m 8.202 ft
Pigtail Diameter, Input	0.25 mm 0.01 in
Pigtail Diameter, Output	0.25 mm 0.01 in

Environmental Specifications

CZ8588-000 | OCC1P-20400-NNNQNF

Qualification Standards

Telcordia GR-1209-CORE | Telcordia GR-1221-CORE

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

