


# FPCE-33YZ

---

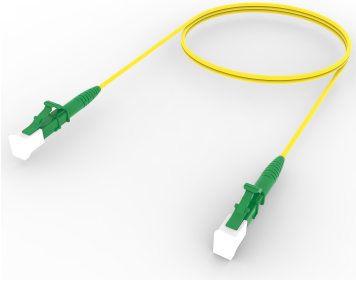

Fiber Optic Patch Cord, singlemode, 1.2 mm LSZH jacket, LC/APC-LC /APC, yellow. tuned

## Product Classification

<b>Regional Availability</b>	Europe   Latin America   Middle East/Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber patch cord, simplex

## General Specifications

<b>Connector A, quantity</b>	1
<b>Color, boot A</b>	Green
<b>Color, connector A</b>	Green
<b>Connector B, quantity</b>	1
<b>Color, boot B</b>	Green
<b>Color, connector B</b>	Green
<b>Interface, Connector A</b>	LC/APC
<b>Interface Feature, connector A</b>	Grade B performance
<b>Interface, Connector B</b>	LC/APC
<b>Interface Feature, connector B</b>	Grade B performance
<b>Jacket Color</b>	Yellow
<b>Total Fibers, quantity</b>	1

## Dimensions

<b>Cable Assembly Length Range (m)</b>	1 – 999
<b>Cable Assembly Length Range (ft)</b>	1 – 999
<b>Diameter Over Jacket</b>	1.2 mm   0.047 in

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
-------------------	------------

# FPCE-33YZ

---

<b>Fiber Type</b>	G.657.A2/B2
<b>Insertion Loss, maximum, connector A</b>	0.25 dB
<b>Insertion Loss, maximum, connector B</b>	0.25 dB
<b>Return Loss, minimum, connector A</b>	65 dB
<b>Return Loss, minimum, connector B</b>	65 dB

## Environmental Specifications

<b>Environmental Space</b>	Low Smoke Zero Halogen (LSZH)
----------------------------	-------------------------------

## Included Products

760243025	–	1.2 mm LSZH Simplex Cable
POC-FO-CAB-SX-8G-1.2MM-YL		