


NG4-MMDCMOR500

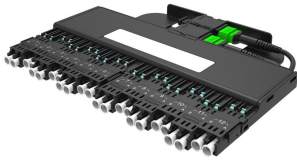

NG4access® MPO Module, multimode OM5, LC-MPO 2x12 fiber, Polarity A, right exit (for MPO module)

- Offers the same craft-friendly interface for LC and SC connectors as the cabled module
- Allow installers to connect an MPO trunk cable to turn up services in rapid installation applications

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber module
Product Brand	NG4access®
Product Series	NG4

General Specifications

Functionality	Breakout
Application	NG4 MPO module
Adapter Color	Lime green
Adapters, quantity, front	12
Body Style	Duplex
Color, front	Black
Color, housing	Black
Color, rear	Black
Interface, front	SC/UPC
Interface, rear	MPO
Polarity	Method A
Total Fibers, quantity	12
Total Ports, quantity, front	24

Dimensions

Height	13.21 mm 0.52 in
Width	159.77 mm 6.29 in
Depth	130.3 mm 5.13 in

NG4-MMDCMOR500

Outline Drawing



Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM5

Environmental Specifications

Operating Temperature	-5 °C to +40 °C (+23 °F to +104 °F)
Storage Temperature	-5 °C to +50 °C (+23 °F to +122 °F)
Relative Humidity	Up to 85%, non-condensing

Packaging and Weights

Packaging quantity	1
Packaging Type	Bag Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

NG4-MMDCMOR500

