


760250710 | TENIO-C6H-TRAY-RR

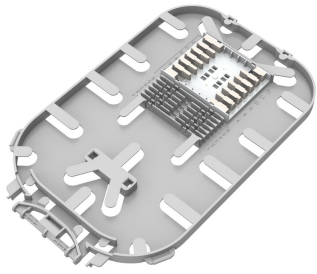

TENIO™ Rollable Ribbon Splice Tray for large closures (CH6 size) for up to 6 Ribbon splice protectors (72 Rollable ribbon fibers) + 12 single fiber heat shrink splice protectors (SMOUV 4.5 mm) per tray. Max capacity of 6 Rollable Ribbon trays per closure

- Fiber and cable technology independent
- Compatible with G652.D optical fiber

Product Classification

Regional Availability	Australia/New Zealand EMEA Latin America
Product Type	Fiber splice tray
Product Series	TENIO

General Specifications

Color	Gray
Splice Tray Chip Type	Heat shrink
Splice Tray Included, quantity	1
Splices per Tray, note	6 x R12 splice protectors and 12 single fiber splice protectors

Dimensions

Height	8 mm 0.315 in
Splice Protector Length, maximum	43 mm 1.693 in
Splice Protector Length, minimum	39 mm 1.535 in
Splice Protector Diameter, maximum	5 mm 0.197 in
Splice Protector Diameter, minimum	3.5 mm 0.138 in

Material Specifications

Material Type	PBT PET
----------------------	-----------

Mechanical Specifications

Minimum Bend Radius, standard	30 mm 1.181 in
--------------------------------------	------------------

Environmental Specifications

760250710 | TENIO-C6H-TRAY-RR

Operating Temperature	-40 °C to +65 °C (-40 °F to +149 °F)
Storage Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Environmental Space	Outdoor

Packaging and Weights

Packaging quantity	6
Packaging Type	Bag Carton
Weight, net	0.1 kg 0.22 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

