


# UNGMPULUAD

Base Product

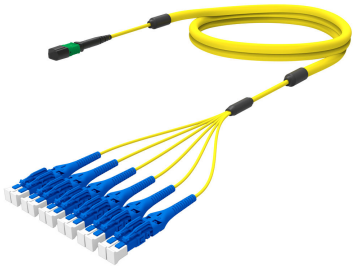

Ultra Low Loss (ULL) Singlemode MPO (Unpinned) to LC/UPC Uniboot, Ruggedized Fanout Cable, 12-Fiber, Low Smoke Zero Halogen

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Ruggedized fanout
<b>Product Brand</b>	SYSTIMAX ULL
<b>Ordering Note</b>	For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications


<b>Color, boot A</b>	Black
<b>Color, connector A</b>	Green
<b>Color, boot B</b>	Blue
<b>Color, connector B</b>	Blue
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Yellow
<b>Interface, Connector A</b>	MPO-12/APC Female
<b>Interface Feature, connector A</b>	Unpinned
<b>Interface, Connector B</b>	LC/UPC
<b>Interface Feature, connector B</b>	Uniboot
<b>Jacket Color</b>	Yellow
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	12
<b>Total Fibers, quantity</b>	12

# UNGEMPLUAD

## Dimensions

<b>Cable Assembly Length Range (m)</b>	3 – 999
<b>Cable Assembly Length Range (ft)</b>	10 – 999

## Ordering Tree

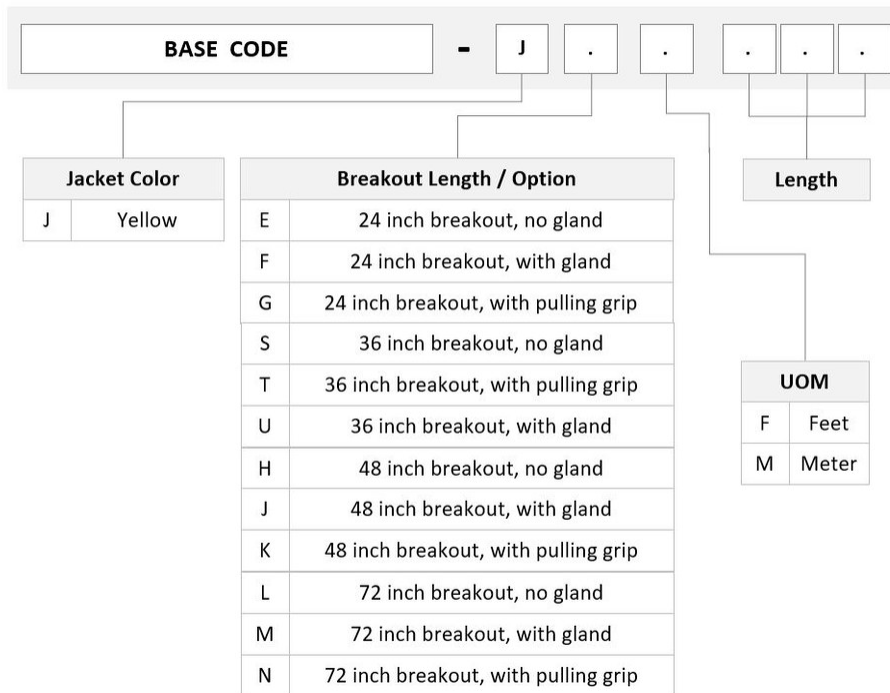

## Mechanical Specifications

<b>Cable Retention Strength, maximum</b>	11.24 lb @ 0 °   4.40 lb @ 90 °
--	---------------------------------

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
<b>Fiber Type</b>	G.657.A2, TeraSPEED®

## Environmental Specifications

<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
<b>Environmental Space</b>	Dual Rated LSZH/Riser   Indoor

# UNGEMPLUAD

---

## Packaging and Weights

**Packaging quantity** 1

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
ANATEL	Compliant



## Included Products

- |                                   |   |  |
|-----------------------------------|---|--|
| 760237971<br>N-012-MP-8G1-F12YL/D | - | Fiber Indoor Cable, Low Smoke Zero Halogen Riser MPO Trunk Cable, 12 fiber, gel-free, singlemode G.657.A2/B2, feet jacket marking, yellow cable jacket color, Dca Flame Rating |
| 860637435                         | - | LC/UPC Connector, Singlemode, Blue, Short Boot   |
| 860638318                         | - | MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm  |