


# 760018820

---

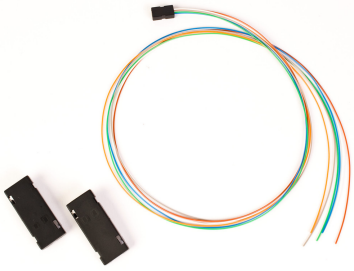

6 Fiber Breakout Kit, loose tube, 900  $\mu\text{m}$

## Product Classification

|                              |   |
|------------------------------|---|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   EMEA   Latin America   North America |
| <b>Portfolio</b>             | SYSTIMAX®   |
| <b>Product Type</b>          | Fiber breakout kit, rectangular                                     |

## General Specifications

|                             |                          |
|-----------------------------|--------------------------|
| <b>Color</b>                | Black                    |
| <b>Compatible Interface</b> | LC   LC, keyed   SC   ST |

## Dimensions

|                            |                   |
|----------------------------|-------------------|
| <b>Height</b>              | 7.62 mm   0.3 in  |
| <b>Width</b>               | 17.78 mm   0.7 in |
| <b>Length</b>              | 43.18 mm   1.7 in |
| <b>Tube Length</b>         | 609.6 mm   24 in  |
| <b>Tube Inner Diameter</b> | 500 $\mu\text{m}$ |
| <b>Tube Outer Diameter</b> | 900 $\mu\text{m}$ |

## Material Specifications

|                              |                                       |
|------------------------------|---------------------------------------|
| <b>Material Type, body</b>   | Acrylonitrile butadiene styrene (ABS) |
| <b>Material Type, tubing</b> | Thermoplastic elastomer (TPE)         |

## Environmental Specifications

|                              |                                      |
|------------------------------|--------------------------------------|
| <b>Operating Temperature</b> | -10 °C to +60 °C (+14 °F to +140 °F) |
|------------------------------|--------------------------------------|

## Packaging and Weights

|                           |   |
|---------------------------|---|
| <b>Included</b>           | Breakout unit   Instruction sheet   Six buffer tubes, 24 in x 900 $\mu\text{m}$   Snap together housing |
| <b>Packaging quantity</b> | 1   |

## Regulatory Compliance/Certifications

| <b>Agency</b> | <b>Classification</b>  |
|---------------|--|
| CHINA-ROHS    | Below maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant  |
| UK-ROHS       | Compliant  |

