


# BLK-RCT-A03C0

---

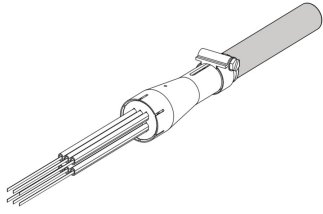

Fiber Optic Ribbon Breakout Kit, 1-12F/ribbon, 108-216F/tube, 8-11 mm central tube outside dia., 3 tubes/leg

## Product Classification

<b>Regional Availability</b>	Latin America   North America
<b>Product Type</b>	Fiber breakout kit, round
<b>Product Series</b>	BLK-R

## General Specifications

<b>Application</b>	For use with ribbon fiber cables
<b>Breakout Legs, quantity</b>	1
<b>Fibers per Ribbon, maximum</b>	12
<b>Fibers per Tube, maximum</b>	324
<b>Tube Type</b>	Ribbon central tube
<b>Tubes per Leg, quantity</b>	3

## Dimensions

<b>Tube Length</b>	5,001.26 mm   196.9 in
<b>Central Tube Outer Diameter</b>	8 mm – 11 mm (0.33 in – 0.43 in)

## Environmental Specifications

<b>Environmental Space</b>	Outdoor
----------------------------	---------

## Packaging and Weights

<b>Packaging quantity</b>	1
<b>Packaging Type</b>	Bag   Carton

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>

# BLK-RCT-A03C0

---

ROHS Compliant/Exempted

UK-ROHS Compliant/Exempted

