


UHXMPMXAL

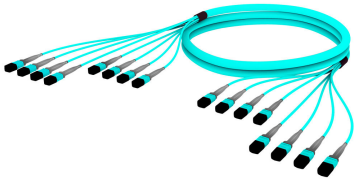

Ultra Low Loss (ULL) Multimode OM4 MPO12 (Unpinned) to MPO12 (Pinned), Armored Pre-terminated Trunk Cable, 96-Fiber, Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Black
Color, boot B	Black
Color, connector A	Aqua
Color, connector B	Aqua
Connector A, quantity	8
Connector B, quantity	8
Construction Type	Armored Stranded
Fibers per Subunit, quantity	12
Furcation Color	Aqua
Interface, Connector A	MPO-12/UPC Female
Interface Feature, connector A	Unpinned
Interface, Connector B	MPO-12/UPC Male
Interface Feature, connector B	Pinned
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)

UHXMPMXAL

Total Fibers, quantity 96

Dimensions

Breakout Length 33 in

Cable Assembly Length Range (m) 3 – 999

Cable Assembly Length Range (ft) 10 – 999

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Plenum

Included Products

- | | | |
|--------------------------------|---|--|
| 760120030
P-096-MZ-5K-F12AQ | - | Fiber indoor cable, LazrSPEED® Plenum MPO Trunk, interlocking aluminum armored with plenum jacket, Multimode OM4, 96 fiber multi-unit with 12 fiber subunits, gel-free, Feet jacket marking, Aqua jacket color |
| 860366210 | - | MPO12, ULTRA LOW LOSS, FEMALE, OM3/4, AQUA, 3mm |
| 860366228 | - | MPO12, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3mm |