


UKGMXUCAF

Base Product

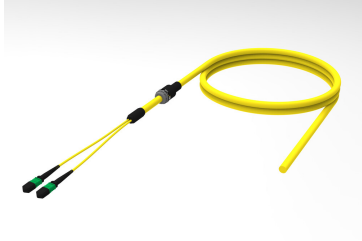

Ultra Low Loss (ULL) Singlemode MPO12 (Pinned) to Unconnectorized, Armored Pre-terminated Trunk Cable, 24-Fiber, Low Smoke Zero Halogen (LSZH)

OBSOLETE

This product was discontinued on: April 30, 2024

Replaced By:

UKGMXUCCF

Singlemode MPO12 APC (pinned) to Unconnectorized Fiber Trunk Cable Assembly, 24-Fiber, Armored Indoor Dual Rated (OFNR/LSZH)

Product Classification

Regional Availability

Asia | Australia/New Zealand | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Fiber trunk cable assembly

Product Brand

SYSTIMAX ULL

Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration | Not available in the United States or Canada

General Specifications

Connector A, quantity	2
Color, boot A	Black
Color, connector A	Green
Connector B, quantity	0
Color, boot B	Black
Color, connector B	Green
Construction Type	Armored Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-12/APC Male
Interface Feature, connector A	Pinned
Interface, Connector B	Unterminated


UKGMXUCAF

Jacket Color	Yellow
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	24

Dimensions

Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

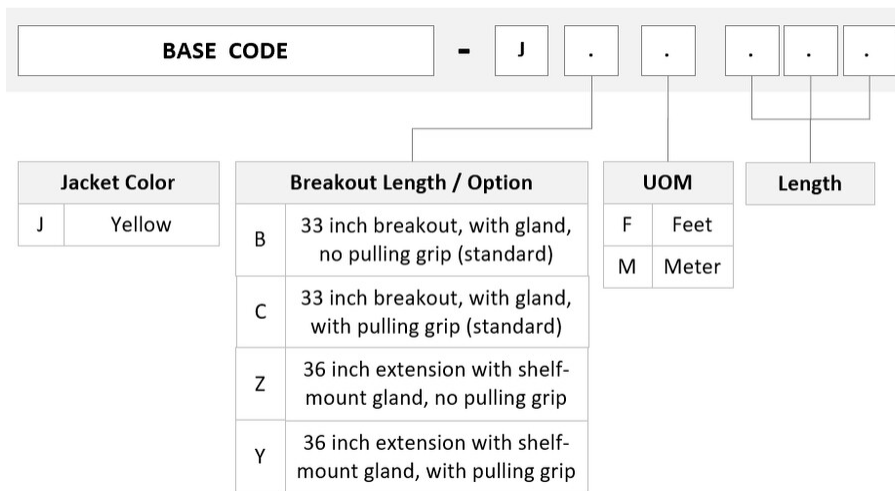

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 ° 4.40 lb @ 90 °
--	---------------------------------

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Dual Rated LSZH/Riser

UKGMXUCAF

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant



Included Products

760249588	-	Fiber indoor cable, Riser/LSZH rated MPO Trunk, interlocking aluminum armored, Singlemode
N-024-MZ-8G1-F12YL		G.657.A2, 24 fiber with 12 fiber subunits, Feet jacket marking, Yellow jacket color
860638317	-	MPO12, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 3mm