

UKVMXMXAG

Base Product



Ultra Low Loss (ULL) Multimode OM5 MPO12 (Pinned) to MPO12 (Pinned), Armored Pre-terminated Trunk Cable, 36-Fiber, Low Smoke Zero Halogen (LSZH)

Product Classification

| | |
|------------------------------|---|
| Regional Availability | Asia Australia/New Zealand Latin America Middle East/Africa North America |
| Portfolio | CommScope® |
| Product Type | Fiber trunk cable assembly |
| Product Brand | SYSTIMAX ULL |
| Ordering Note | For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration Not available in the United States or Canada |

General Specifications

| | |
|---------------------------------------|-------------------------|
| Connector A, quantity | 3 |
| Color, boot A | Black |
| Color, connector A | Lime green |
| Connector B, quantity | 3 |
| Color, boot B | Black |
| Color, connector B | Lime green |
| Construction Type | Armored Stranded |
| Furcation Color | Lime green |
| Interface, Connector A | MPO-12/UPC Male |
| Interface Feature, connector A | Pinned |
| Interface, Connector B | MPO-12/UPC Male |
| Interface Feature, connector B | Pinned |
| Jacket Color | Lime green |
| Polarity | Method B Enhanced (ULL) |


UKVMXMAG

| | |
|-------------------------------------|----|
| Fibers per Subunit, quantity | 12 |
| Total Fibers, quantity | 36 |

Dimensions

| | |
|---|----------|
| Breakout Length | 33 in |
| Cable Assembly Length Range (m) | 3 – 999 |
| Cable Assembly Length Range (ft) | 10 – 999 |

Ordering Tree

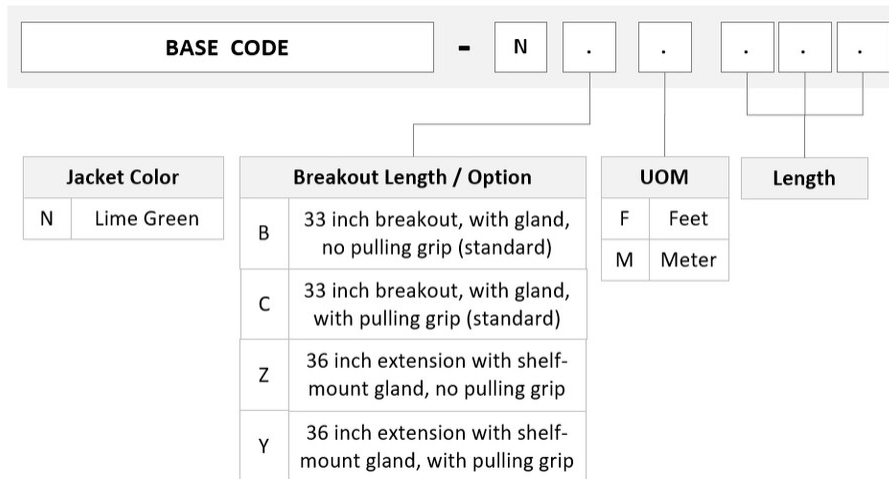

Mechanical Specifications

| | |
|--|---------------------------------|
| Cable Retention Strength, maximum | 11.24 lb @ 0 ° 4.40 lb @ 90 ° |
|--|---------------------------------|

Optical Specifications

| | |
|-------------------|-----------------|
| Fiber Mode | Multimode |
| Fiber Type | OM5, LazrSPEED® |

Environmental Specifications

| | |
|------------------------------|--------------------------------------|
| Operating Temperature | -10 °C to +60 °C (+14 °F to +140 °F) |
| Environmental Space | Dual Rated LSZH/Riser Indoor |

Included Products

| | | |
|-----------|---|--|
| 760230292 | - | Fiber indoor cable, LazrSPEED® Riser/LSZH rated, MPO Trunk, interlocking aluminum armored, |
|-----------|---|--|

UKVMXMXAG

N-036-MZ-5G-F12LM

Multimode OM5, 36 fiber multi-unit with 12 fiber subunits, Feet jacket marking, Lime-green jacket color

860617240

– MPO12, ULTRA LOW LOSS, MALE, OM5, LIME, 3mm