


RCPB-1C2DUM03100

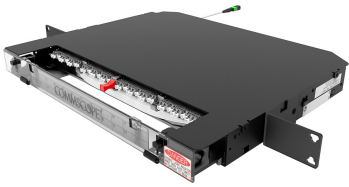

RapidFiber® Termination Panel, 24-Position LC to MPO, 1RU, indoor /outdoor, multimode (OM3), 31 m, black

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel, with rapid cable
Product Brand	RapidFiber®
Product Series	RCP

General Specifications


Functionality	Patching
Body Style	Symmetrical
Cable Exit Location	Rear, left side
Cable Stub Type	Indoor/outdoor, microcable
Color	Black
Color, front	Black
Door Type, front	Hinged Slide latch Transparent
Growth Configuration	Fully loaded
Interface, front	LC
Interface Feature, front	Standard
Interface, rear	MPO
Patch Cord Entry Location	Front, left side Front, right side
Rack Type	EIA 19 in EIA 23 in
Rack Units	1
Shelf Movement	Sliding
Total Fibers, quantity	24
Total Ports, quantity	24
Transmission Standards	IEC 60794-2 ISO/IEC 11801 TIA/EIA-568-B.3

Dimensions

RCPB-1C2DUM03100

Height	44.45 mm 1.75 in
Width	482.6 mm 19 in
Depth	381 mm 15 in
Cable Stub Length	31 m 101.706 ft

Ordering Tree

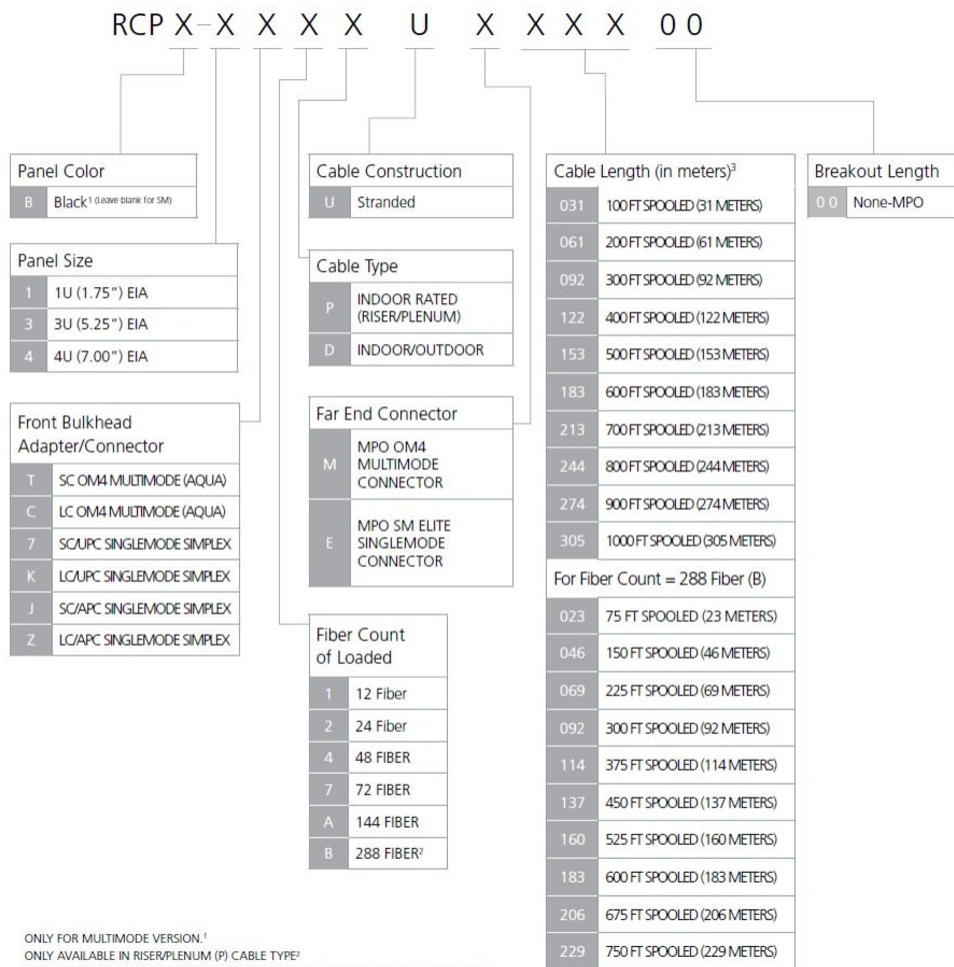

ONLY FOR MULTIMODE VERSION.¹
 ONLY AVAILABLE IN RISER/PLENUM (P) CABLE TYPE²
 RAPID PANEL IS DESIGNED AND QUALIFIED FOR UP TO 1000'³ (305 METERS) OF CABLE.³

Material Specifications

Finish	Powder coated
Material Type	Steel

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM3, bend insensitive

RCPB-1C2DUM03100

Environmental Specifications

Operating Temperature	-5 °C to +55 °C (+23 °F to +131 °F)
Storage Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Relative Humidity	5%–85%, non-condensing
Qualification Standards	NEBS Level 3 Telcordia GR-1435 Telcordia GR-326 Telcordia GR-409 UL 1863

Packaging and Weights

Packaging quantity	1
---------------------------	---

Included Products

760236227 Z-012-MD-5E1-F36BK/D	–	Indoor/Outdoor Low Smoke Zero Halogen MicroDistribution Cable, 12-Fiber
-----------------------------------	---	---