


MC-PK8-DSH

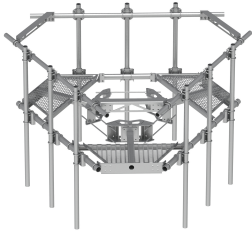

Low-Profile Co-location Platform Kit for 12in to 38in OD Monopoles, 8 ft face, (9) 2-7/8" OD x 96" Pipes, with Support Rail Kit

Please contact CommScope for detailed drawings prior to ordering.

Product Classification

Portfolio	CommScope®
Product Type	Monopole platform kit
Ordering Note	CommScope® non-standard product
Warranty	One year

General Specifications

Mounting	Monopole, 305–965 mm (12–38 in) OD
Pipe, quantity	9
Sectors, quantity	3

Dimensions

Height	2,438.4 mm 96 in
Face Width	2,438 m 8 ft
Width	2,438.4 mm 96 in
Pipe Length	2,438.4 mm 96 in
Face Support Pipe Diameter	88.9 mm 3.5 in
Mounting Diameter, maximum	965.2 mm 38 in
Mounting Diameter, minimum	304.8 mm 12 in
Pipe Outer Diameter	73.025 mm 2.875 in
Stand-off Distance	914.4 mm 36 in

Material Specifications

Material Type	Hot dip galvanized steel
----------------------	--------------------------

Mechanical Specifications

Wind Rating Test Method	TIA/EIA-222
--------------------------------	-------------

MC-PK8-DSH

Packaging and Weights

Included	Hardware Plain end pipes (9) Platform Rail Ring mount
Packaging quantity	1
Weight, net	817.147 kg 1,801.5 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



* Footnotes

Warranty	For more information, please consult our Product Warranty guidelines
-----------------	--