


# U3GRXR8Q

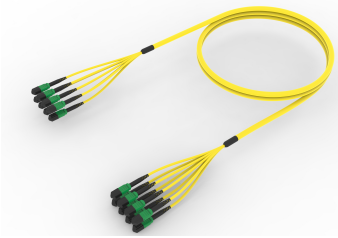

Ultra Low Loss (ULL) Singlemode G.657.A2 MPO16 (Pinned) to MPO16 (Pinned), Fiber Trunk Cable Assembly, 128-Fiber, LSZH B2ca

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Europe   |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Fiber trunk cable assembly   |
| <b>Product Brand</b>         | Propel   SYSTIMAX ULL  |
| <b>Ordering Note</b>         | For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications

|                                     |                         |
|-------------------------------------|-------------------------|
| <b>Connector A, quantity</b>        | 8                       |
| <b>Color, boot A</b>                | Black                   |
| <b>Color, connector A</b>           | Green                   |
| <b>Connector B, quantity</b>        | 8                       |
| <b>Color, boot B</b>                | Black                   |
| <b>Color, connector B</b>           | Green                   |
| <b>Construction Type</b>            | Stranded                |
| <b>Furcation Color</b>              | Yellow                  |
| <b>Interface, Connector A</b>       | MPO-16/APC Male         |
| <b>Interface, Connector B</b>       | MPO-16/APC Male         |
| <b>Jacket Color</b>                 | Yellow                  |
| <b>Polarity</b>                     | Method B Enhanced (ULL) |
| <b>Fibers per Subunit, quantity</b> | 16                      |
| <b>Total Fibers, quantity</b>       | 128                     |

## Dimensions


|  |         |
|--|---------|
| <b>Breakout Length</b>                 | 22 in   |
| <b>Cable Assembly Length Range (m)</b> | 3 – 305 |

# U3GRXR8Q

Cable Assembly Length Range (ft)

10 – 999

## Ordering Tree

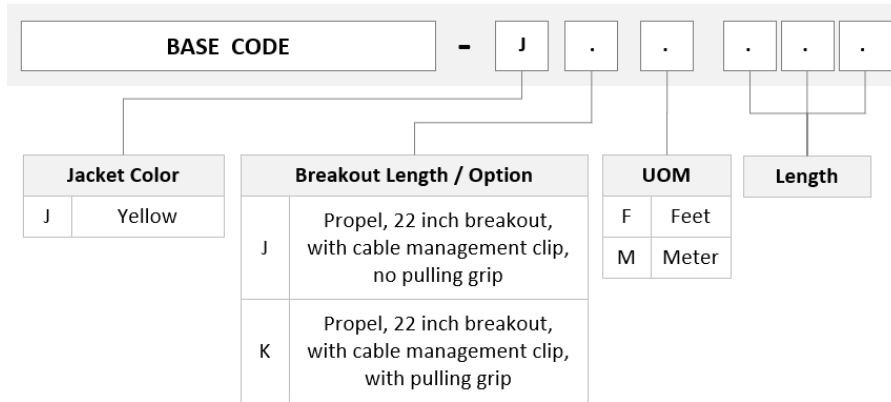

## Mechanical Specifications

**Cable Retention Strength, maximum**

11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode**

Singlemode

**Fiber Type**

G.657.A2, TeraSPEED®

## Environmental Specifications

**Operating Temperature**

-10 °C to +60 °C (+14 °F to +140 °F)

**EN50575 CPR Cable EuroClass Fire Performance**

B2ca

**Environmental Space**

Indoor | Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

**Agency**

**Classification**

CHINA-ROHS

Above maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted



# U3GRXR8Q

---

## Included Products

- 760251078  
N-128-MP-8G1-F16YL/30T/B2 – Fiber indoor cable, TeraSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 128 fiber with 16-fiber 3.0 mm subunits, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, B2ca flame rating
- 860661398 – Fiber Optic Connector Kit, singlemode, OS2, MPO-16/APC, ULL, pinned, green, for 3 mm cable