


UJVVQVQZTH

Base Product

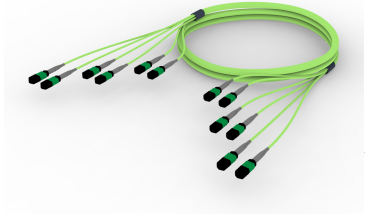

Ultra Low Loss (ULL) OM5 MPO APC (Non-Pinned) to MPO APC (Pinned), Fiber Trunk Cable Assembly, 48-Fiber, Dual Rated (OFNR /LSZH)

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	6
Color, boot A	Gray
Color, connector A	Green
Connector B, quantity	6
Color, boot B	Gray
Color, connector B	Green
Construction Type	Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-08/APC Female
Interface, Connector B	MPO-08/APC Male
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	48

Dimensions

Breakout Length	22 in
------------------------	-------



Included Products

- 760248174
N-048-MP-5G-F08AQ/20T/D
 - Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 48 fiber multi-unit with 8 fiber 2.0mm subunits, Gel-free, Multimode OM5, Feet jacket marking, Aqua jacket color, Dca flame rating
- 860662230
 - MPO8,ULL,Multimode,MALE,APC,GREEN,2 mm
- 860662232
 - MPO8,ULL,Multimode,FEMALE,APC,GREEN,2 mm