


# UJXQVQZTN

## Base Product

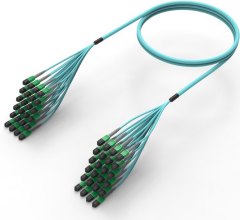

Ultra Low Loss (ULL) OM4 MPO APC (Pinned) to MPO APC (unPinned), Fiber Trunk Cable Assembly, 192-Fiber, Dual Rated (OFNR/LSZH)

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America   |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Fiber trunk cable assembly   |
| <b>Product Brand</b>         | Propel   SYSTIMAX ULL  |
| <b>Ordering Note</b>         | For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications

|                                     |                         |
|-------------------------------------|-------------------------|
| <b>Connector A, quantity</b>        | 24                      |
| <b>Color, boot A</b>                | Gray                    |
| <b>Color, connector A</b>           | Green                   |
| <b>Connector B, quantity</b>        | 24                      |
| <b>Color, boot B</b>                | Gray                    |
| <b>Color, connector B</b>           | Green                   |
| <b>Construction Type</b>            | Stranded                |
| <b>Furcation Color</b>              | Aqua                    |
| <b>Interface, Connector A</b>       | MPO-08/APC Female       |
| <b>Interface, Connector B</b>       | MPO-08/APC Male         |
| <b>Jacket Color</b>                 | Aqua                    |
| <b>Polarity</b>                     | Method B Enhanced (ULL) |
| <b>Fibers per Subunit, quantity</b> | 8                       |
| <b>Total Fibers, quantity</b>       | 192                     |

## Dimensions

# UJXQVQZTN

|   |          |
|---|----------|
| <b>Breakout Length</b>                  | 22 in    |
| <b>Cable Assembly Length Range (m)</b>  | 3 – 305  |
| <b>Cable Assembly Length Range (ft)</b> | 10 – 999 |

## Ordering Tree



## Mechanical Specifications

|  |                                 |
|--|---------------------------------|
| <b>Cable Retention Strength, maximum</b> | 11.24 lb @ 0 °   4.40 lb @ 90 ° |
|--|---------------------------------|

## Optical Specifications

|                   |                 |
|-------------------|-----------------|
| <b>Fiber Mode</b> | Multimode       |
| <b>Fiber Type</b> | OM4, LazrSPEED® |

## Environmental Specifications

|                              |                                      |
|------------------------------|--------------------------------------|
| <b>Operating Temperature</b> | -10 °C to +60 °C (+14 °F to +140 °F) |
| <b>Environmental Space</b>   | Dual Rated LSZH/Riser   Indoor       |

## Regulatory Compliance/Certifications

|               |  |
|---------------|--|
| <b>Agency</b> | <b>Classification</b>  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |

## Included Products

|                                       |   |  |
|---------------------------------------|---|--|
| 760253125<br>N-192-MP-5K-F08AQ/20T/B2 | - | Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 192 fiber with 2.0 mm Subunits, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color, B2ca flame |
|---------------------------------------|---|--|

# UJXQVQZTN

---

|           | rating                                     |
|-----------|--|
| 860662230 | - MPO8,ULL,Multimode,MALE,APC,GREEN,2 mm   |
| 860662232 | - MPO8,ULL,Multimode,FEMALE,APC,GREEN,2 mm |