


UQV2X2EBH

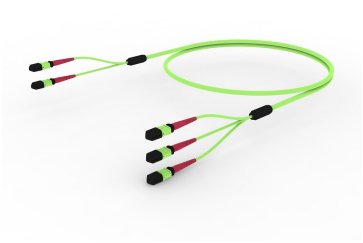

Ultra Low Loss (ULL) OM5, 2X3, MPO24 (Pinned) to MPO24 (Non-Pinned-QSFP), 48-Fiber, Conversion Array, Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber conversion array cable assembly
Product Brand	PropeI SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Connector A, quantity	2
Color, boot A	Red
Color, connector A	Lime green
Connector B, quantity	3
Color, boot B	Red
Color, connector B	Lime green
Construction Type	Stranded
Fibers per Subunit, quantity	24
Furcation Color	Lime green
Interface, Connector A	MPO-24/UPC Male
Interface, Connector B	MPO-24/UPC Female
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Total Fibers, quantity	48

Dimensions

UQV2X2EBH

Breakout Length	12 in 24 in 36 in 48 in 60 in 72 in
Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

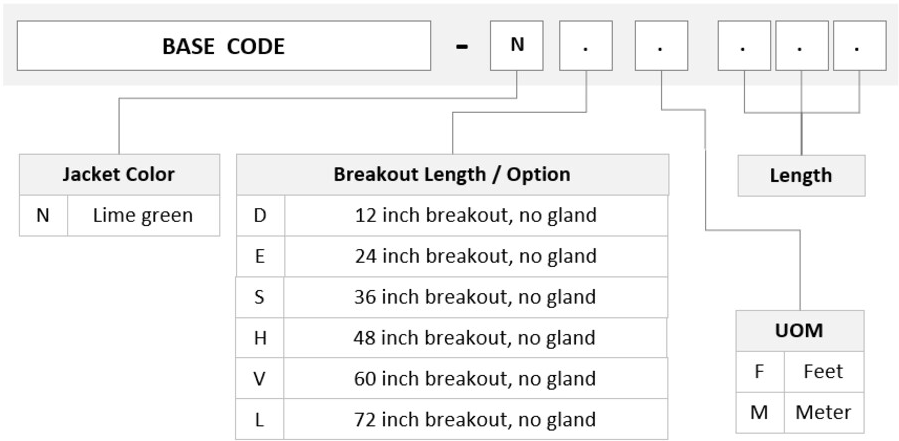

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 ° 4.40 lb @ 90 °
-----------------------------------	---------------------------------

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM5, LazrSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Indoor Plenum

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

UQV2X2EBH



Included Products

760235977	–	Fiber indoor cable, LazrSPEED® Plenum for MPO Trunks, 48 fiber with 24 fiber subunits,
P-048-MP-5G-F24LM		Multimode OM5, Feet jacket marking, Lime green jacket color
860634625	–	LazrSPEED® Elite MPO Male 24 Fiber Connector, lime green
860662279	–	MPO24,FEMALE,OM5,LIME,3.0MM