


# URVQPLUF8

## Base Product

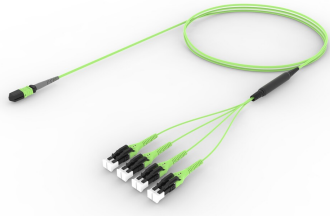

Ultra Low Loss (ULL) OM5 MPO8 (Non-Pinned) to LC/UPC Uniboot, Fiber Array Cable Assembly, 8-Fiber, Dual Rated (OFNR/LSZH)

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber array cable assembly
<b>Product Brand</b>	Propel   SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

<b>Connector A, quantity</b>	1
<b>Color, boot A</b>	Gray
<b>Color, connector A</b>	Lime green
<b>Connector B, quantity</b>	4
<b>Color, boot B</b>	Lime green
<b>Color, connector B</b>	Lime green
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Lime green
<b>Interface, Connector A</b>	MPO-08/UPC Female
<b>Interface, Connector B</b>	LC/UPC
<b>Jacket Color</b>	Lime green
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	8
<b>Total Fibers, quantity</b>	8

## Dimensions

<b>Breakout Length</b>	12 in   24 in   36 in   48 in   60 in   72 in
------------------------	---



# URVQPLUF8

---

- 860650410 – LazrSPEED® LC UniBoot 2.0 mm Multimode/LC UNIBOOT CONNECTOR KIT
- 860659026 – MPO-08, ULTRA LOW LOSS, FEMALE, OM5, LIME-GREEN, 2mm