


760253560 | FOST-ACC-D-TRAY-96

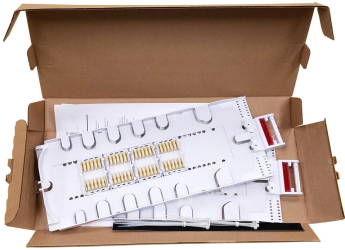

FOST splice tray, 96 stranded fiber splicing per tray

Will hold 24 splice protectors.

Product Classification

| | |
|------------------------------|---|
| Regional Availability | Asia Australia/New Zealand EMEA Latin America North America |
| Portfolio | CommScope® |
| Product Type | Fiber splice tray |

General Specifications

| | |
|---------------------------------------|----------|
| Splice Tray Capacity, quantity | 96 |
| Splice Tray Chip Type | SMOUV |
| Splice Trays | Included |
| Splices per Tray, quantity | 96 |
| Splicing Capacity, maximum | 96 |
| Splicing Type | Stranded |

Dimensions

| | |
|--------------|--------------------|
| Width | 153 mm 6.024 in |
| Depth | 377 mm 14.843 in |

Environmental Specifications

| | |
|--------------------------------|----|
| Qualification Standards | UL |
|--------------------------------|----|

Packaging and Weights

| | |
|---------------------------|---|
| Packaging quantity | 1 |
|---------------------------|---|

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|-----------------------------------|
| CHINA-ROHS | Below maximum concentration value |
| ROHS | Compliant |

UK-ROHS

Compliant

