


WSC-SH021210

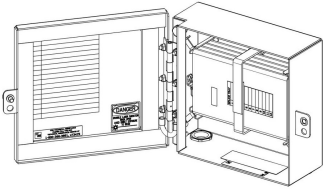

WSC Wall Splice Cabinet for MDU applications, indoor/outdoor, for up to 48 fibers, includes 1 splice tray with heat shrink fusion, no key lock

Product Classification

Regional Availability	North America
Portfolio	CommScope®
Product Type	Fiber wall box

General Specifications

Functionality	Splicing
Access	Front
Cable Color	White
Cable Type	Pigtails - Stranded
Door, quantity	1
Enclosure Color	Putty white
Front Door Type	Single hinged
Interface	Splicing only
Lock Type	Locking bolt
Mounting	Wall
Splice Trays	Included
Splicing Type	Heat shrink

Dimensions

Height	273 mm 10.748 in
Width	255 mm 10.039 in
Depth	89 mm 3.504 in

Environmental Specifications

Environmental Space	Outdoor
Qualification Standards	NEMA, Type 4

WSC-SH021210

Packaging and Weights

Packaging quantity	1
Packaging Type	Box Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant

