


MC-CP14L-B

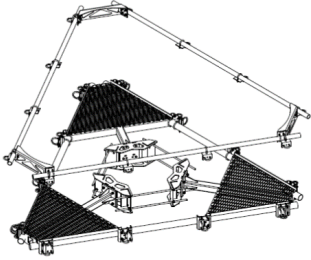

3-Sector Monopole Co-location Platform Base Kit, 30 in to 60 in OD, 14 ft 6 in face, pipe ordered separately

OBSOLETE

This product was discontinued on: March 9, 2022

Replaced By:

MC-CP14M-B

3-Sector Monopole Co-location Platform Base Kit, 12 in to 50 in OD, 14 ft 6 in face, pipe ordered separately

Product Classification

Product Type Monopole platform kit

General Specifications

Mounting Monopole, 762–1524 mm (30–60 in) OD

Pipe, quantity 0

Sectors, quantity 3

Dimensions

Face Width 4.42 m | 14.5 ft

Width 4,419.6 mm | 174 in

Mounting Diameter, maximum 1524 mm | 60 in

Mounting Diameter, minimum 762 mm | 30 in

Pipe Outer Diameter 60.96 mm | 2.4 in

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

Wind Rating 120 mph (BWS) at 100 ft AGL | 140 mph (3-second gust) at 150 ft AGL using Exposure D per FBC

Wind Rating Test Method TIA/EIA-222

MC-CP14L-B

Packaging and Weights

Included	Platform Rail Ring mount
Packaging quantity	1
Weight, net	757.046 kg 1669 lb

* Footnotes

Wind Rating	BWS—Base Wind Speed; FBC—Florida Building Code
--------------------	--