


# MC-CP14S-12-96

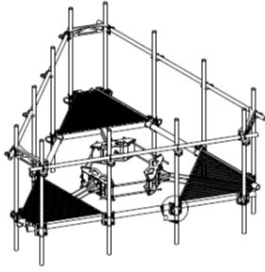

3-Sector Monopole Co-location Platform Kit, 10 in to 30 in OD, 14 ft 6 in face, includes twelve 96 in pipes

## OBSOLETE

This product was discontinued on: March 9, 2022

### Replaced By:

MC-CP14M-12-96      3-Sector Monopole Co-location Platform Kit, 12 in to 50 in OD, 14 ft 6 in face, includes twelve 96 in pipes

## Product Classification

**Product Type**                      Monopole platform kit

## General Specifications

**Mounting**                              Monopole, 254–762 mm (10–30 in) OD  
**Pipe, quantity**                      12  
**Sectors, quantity**                      3

## Dimensions

**Height**                                      2,438.4 mm | 96 in  
**Face Width**                              4.42 m | 14.5 ft  
**Width**                                        4,419.6 mm | 174 in  
**Pipe Length**                              2,438.4 mm | 96 in  
**Mounting Diameter, maximum**      762 mm | 30 in  
**Mounting Diameter, minimum**      254 mm | 10 in  
**Pipe Outer Diameter**                  60.96 mm | 2.4 in

## Material Specifications

**Material Type**                          Hot dip galvanized steel

## Mechanical Specifications

# MC-CP14S-12-96

---

<b>Wind Rating</b>	120 mph (BWS) at 100 ft AGL   140 mph (3-second gust) at 150 ft AGL using Exposure D per FBC
<b>Wind Rating Test Method</b>	TIA/EIA-222

## Packaging and Weights

<b>Included</b>	Plain end pipes (12)   Platform   Rail   Ring mount
<b>Packaging quantity</b>	1
<b>Weight, net</b>	884.959 kg   1951 lb

## \* Footnotes

<b>Wind Rating</b>	BWS—Base Wind Speed; FBC—Florida Building Code
--------------------	--