


MC-PM12M-12C-H10

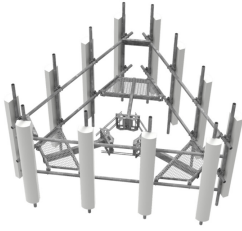

ATLAS 12 ft Monopole Platform with (12) 2.88" OD x 120" Antenna Pipes. Includes Top Rail Kit.

The innovative ATLAS Monopole Platform provides high-load performance, Lower EPA, and reduced weight – all with a single-point tower connection.

NOTE: Engineering loading based on Antenna pipes vertically centered on main horizontal face.

Product Classification

Product Type	Monopole platform kit
Product Series	ATLAS

General Specifications

Mounting	Monopole, 304.8–1270 mm (12–50 in) OD
Pipe, quantity	12
Sectors, quantity	3

Dimensions

Height	3,048 mm 120 in
Face Width	3.81 m 12.5 ft
Platform Width	3,810 mm 150 in
Width	3,810 mm 150 in
Pipe Length	3,048 mm 120 in
Face Support Pipe Diameter	73.025 mm 2.875 in
Mounting Diameter, maximum	1,143 mm 45 in
Mounting Diameter, minimum	304.8 mm 12 in
Pipe Outer Diameter	73.025 mm 2.875 in

Material Specifications

Material Type	Hot dip galvanized steel
----------------------	--------------------------

Mechanical Specifications

Wind Rating	For Specifications, please contact steelproducts@commscope.com or call 800-255-1479
Wind Rating Test Method	TIA/EIA-222

MC-PM12M-12C-H10

Packaging and Weights

Included	Plain end pipes (12) Platform Rail Ring mount
Packaging quantity	1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



* Footnotes

Wind Rating	BWS—Base Wind Speed; FBC—Florida Building Code
--------------------	--