


MC-HP14M-B

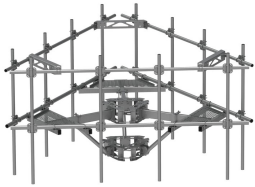

3-Sector Monopole Co-location Platform Base Kit, 12 in to 50 in OD, 12 ft 6 in face, pipe ordered separately

Product Classification

Product Type	Co-location platform
Ordering Note	NSTD445 Compliant

General Specifications

Mounting	Monopole, 304.8–1270 mm (12–50 in) OD
Pipe, quantity	0
Sectors, quantity	3

Dimensions

Face Width	4.42 m 14.5 ft
Width	4,419.6 mm 174 in
Mounting Diameter, maximum	1270 mm 50 in
Mounting Diameter, minimum	304.8 mm 12 in
Pipe Outer Diameter	60.96 mm 2.4 in

Material Specifications

Material Type	Hot dip galvanized steel
----------------------	--------------------------

Mechanical Specifications

Wind Rating	120 mph (BWS) at 100 ft AGL 140 mph (3-second gust) at 150 ft AGL using Exposure D per FBC
Wind Rating Test Method	TIA/EIA-222

Packaging and Weights

Included	Platform Rail Ring mount
-----------------	------------------------------

MC-HP14M-B

Packaging quantity 1
Weight, net 598.969 kg | 1,320.5 lb

* Footnotes

Wind Rating BWS—Base Wind Speed; FBC—Florida Building Code