


FD3-AJ864J00DFBP4

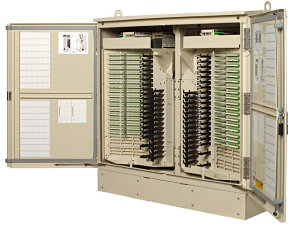

FDH 3000 Fiber Distribution Large Cabinet, 864F, SC/APC, no splitters, dielectric ribbon, 100 ft, 48F

Product Classification

Regional Availability	North America
Product Type	Fiber distribution hub
Product Series	FDH 3000

General Specifications

Access	Front and rear door
Cable Type	Dielectric - Ribbon
Color	Putty white
Distribution Cables, quantity	2
Distribution Ports, quantity	864
Fibers per Distribution Cable, quantity	432
Fibers per Feeder Cable, quantity	48
Interface, Input	SC
Interface Feature, Input	APC
Mounting	Pad
Splitter Slots, quantity	48

Dimensions

Height	1,238.25 mm 48.75 in
Width	1,220.47 mm 48.05 in
Depth	497.33 mm 19.58 in
Cable Length	30.48 m 100 ft
Enclosure Size	Large

Material Specifications

Finish	Powder coated
Material Type	Aluminum

FD3-AJ864J00DFBP4

Environmental Specifications

Environmental Space Above ground

Packaging and Weights

Packaging quantity 1

Packaging Type Pallet