


# MC-PK12S4-B

---

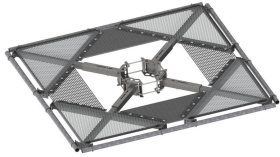

4-Sector Monopole Co-location Platform kit, 10 in to 30 in OD, 12 ft 6 in face, pipe ordered separately

## Product Classification

**Product Type** Monopole platform kit

## General Specifications

**Mounting** Monopole, 254–762 mm (10–30 in) OD

**Pipe, quantity** 0

**Sectors, quantity** 4

## Dimensions

**Height** 254 mm | 10 in

**Face Width** 3.81 m | 12.5 ft

**Width** 3810 mm | 150 in

**Length** 914.4 mm | 36 in

**Face Support Pipe Diameter** 88.9 mm | 3.5 in

**Mounting Diameter, maximum** 762 mm | 30 in

**Mounting Diameter, minimum** 254 mm | 10 in

**Pipe Outer Diameter** 0 mm | 0 in

**Stand-off Distance** 914.4 mm | 36 in

**Mounting Circumference, maximum** 2,392.68 mm | 94.2 in

**Mounting Circumference, minimum** 797.56 mm | 31.4 in

## Material Specifications

**Material Type** Hot dip galvanized steel

## Mechanical Specifications

**Wind Rating** 120 mph (BWS) at 100 ft AGL | 140 mph (3-second gust) at 150 ft AGL using Exposure D

# MC-PK12S4-B

---

per FBC

**Wind Rating Criteria**

Four 72 in x 12 in panel antennas per sector

**Wind Rating Test Method**

TIA/EIA-222

## Packaging and Weights

**Included**

Platform | Ring mount

**Packaging quantity**

1

**Weight, net**

1,043.308 kg | 2,300.1 lb

## \* Footnotes

**Wind Rating**

BWS—Base Wind Speed; FBC—Florida Building Code