


# 1RU-SP3116004 | 1RU SPLTR PNL (4) 1X16 APC/SC

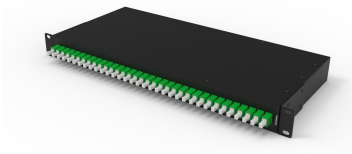

1RU panel, 1X16 split ratio, 4 splitters, SC/APC connectors

## Product Classification

Regional Availability	Asia   Australia/New Zealand   China   EMEA   India   Latin America   North America
Product Type	Splitter module
Product Series	1RU

## General Specifications

Functionality	Splitting
Technology Type	Planar lightwave circuit (PLC)
Distribution Type	1 x 16 splitter
Interface, Input	SC/APC
Interface, Output	SC/APC
Splitter, quantity	4

## Dimensions

Height	43.69 mm   1.72 in
Width	482.6 mm   19 in
Length	199.89 mm   7.87 in

## Optical Specifications

Directivity, minimum	55 dB
Polarization Dependent Loss, maximum	0.3 dB
Uniformity, maximum	1.55 dB
Wavelength Range	1260–1650 nm
Insertion Loss, Splitter, maximum	14.2 dB
Return Loss, Splitter, minimum	50 dB

## Environmental Specifications

1RU-SP3116004

|

1RU SPLTR PNL (4) 1X16 APC/SC

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Relative Humidity	5%–95%, non-condensing

Packaging and Weights

Packaging quantity	1
--------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant

