

URVLCCLCGD

Ultra Low Loss (ULL) OM5 LC/UPC to LC/UPC Fanout Cable, 12-Fiber, LSZH & OFNR

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Lime green
Color, connector A	Black
Color, boot B	Lime green
Color, connector B	Black
Construction Type	Stranded
Furcation Color	Lime green
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Jacket Color	Lime green
Fibers per Subunit, quantity	12
Total Fibers, quantity	12

Dimensions

Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	10 – 999
Diameter Over Jacket	3 mm 0.118 in

Ordering Tree

URVLCCLCGD

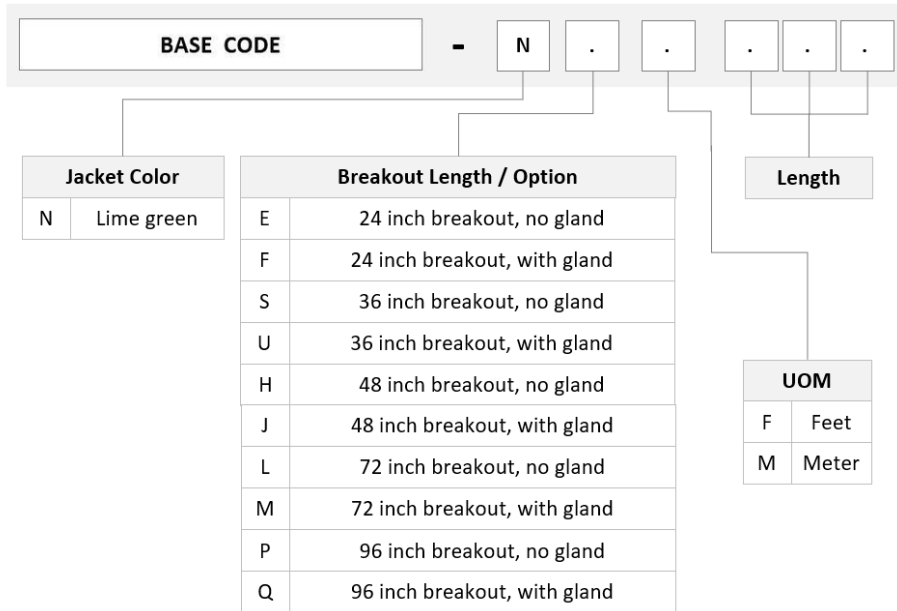

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode Multimode

Fiber Type OM5, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/OFNR | Indoor

Regulatory Compliance/Certifications

Agency **Classification**

ANATEL Compliant



Included Products

760229039 - Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser Light Duty for MPO

URVLCCLCGD

N-012-MP-5G-F30LM/D

Patchcords, 12 fiber, Multimode OM5, Gel-free, Feet jacket marking, Lime green jacket color,
Dca Flame rating