

Singlemode MPO (Non-Pinned) to Unconnectorized InstaPATCH® 360 Pre-terminated Trunk Cable, 12-Fiber, Low Smoke Zero Halogen

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber trunk cable assembly
<b>Product Brand</b>	SYSTIMAX InstaPATCH® 360
<b>Ordering Note</b>	For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration   Not available in the United States or Canada

## General Specifications

<b>Color, boot A</b>	Black
<b>Color, boot B</b>	Black
<b>Color, connector A</b>	Green
<b>Color, connector B</b>	Green
<b>Construction Type</b>	Stranded
<b>Fibers per Subunit, quantity</b>	12
<b>Furcation Color</b>	Yellow
<b>Interface, Connector A</b>	MPO-12/APC Female
<b>Interface, Connector B</b>	MPO-12/APC Female
<b>Jacket Color</b>	Yellow
<b>Polarity</b>	Method B (LL)
<b>Total Fibers, quantity</b>	12


## Dimensions

<b>Breakout Length</b>	33 in
------------------------	-------

# FJWMPUCAD

<b>Cable Assembly Length Range (m)</b>	3 – 999
<b>Cable Assembly Length Range (ft)</b>	10 – 999

## Ordering Tree

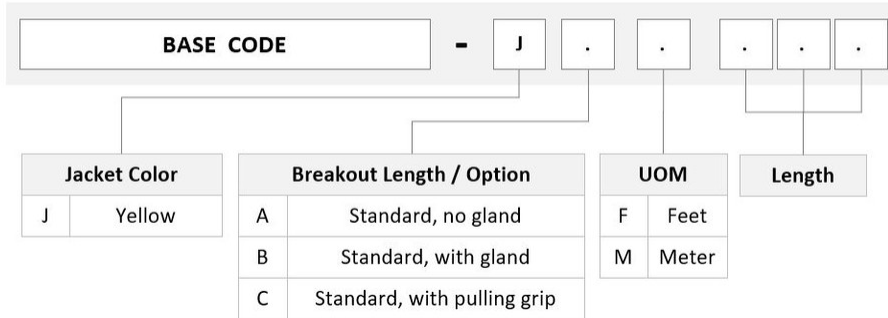

## Mechanical Specifications

<b>Cable Retention Strength, maximum</b>	11.24 lb @ 0°   4.40 lb @ 90°
--	-------------------------------

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
<b>Fiber Type</b>	G.652.D   G.657.A1, TeraSPEED®

## Environmental Specifications

<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
<b>Environmental Space</b>	Dual Rated LSZH/Riser   Indoor

## Included Products

760050328	–	Fiber OSP cable, TeraSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 12 fiber, Singlemode G.652.D and G.657.A1, Feet jacket marking, Yellow jacket color, Dca flame rating
N-012-MP-8W-F12YL/D		
860366137	–	MPO12, LOW LOSS, FEMALE, Singlemode, GREEN, 3mm