


760251757 | OCP-EC-02MASCA-XX

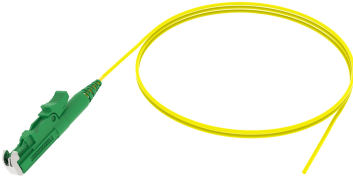

Fiber Optic Pigtail, Simplex, Singlemode, LSZH, 2.4 mm diameter, tuned, Grade B, LSH/APC to Stub, yellow, 2 m

Product Classification

Regional Availability	EMEA
Product Type	Fiber pigtail, jacketed
Product Series	OCP

General Specifications

Connector A, quantity	1
Color, boot A	Green
Color, connector A	Green
Interface, Connector A	LSH/APC
Jacket Color	Yellow
Total Fibers, quantity	1

Dimensions

Cord Length	2 m 6.562 ft
Diameter Over Jacket	2.4 mm 0.094 in

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A1, TeraSPEED®
Performance Grade	Superior B grade
Insertion Loss, maximum, connector A	0.25 dB
Return Loss, minimum, connector A	60 dB

Environmental Specifications

Environmental Space	Low Smoke Zero Halogen (LSZH)
----------------------------	-------------------------------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



* Footnotes

Performance Grade	Guarantee to meet IEC 61755-1 Random Mating requirement
--------------------------	---