


# VZWSMART-MSK14 | UNIVERSAL ADJUSTABLE CROSSOVER

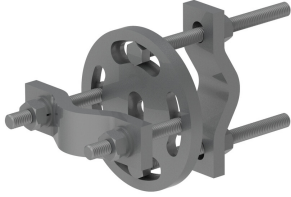

## UNIVERSAL ADJUSTABLE CROSSOVER

Universal Adjustable Crossover Plate, connects up to 2-7/8" OD x 3-1/2" OD Pipe

### Product Classification

<b>Product Type</b>	Clamp plate
<b>Ordering Note</b>	ANDREW® non-standard product

### General Specifications

<b>Mounting</b>	Crossover plate
-----------------	-----------------

### Dimensions

<b>Height</b>	139.7 mm   5.5 in
<b>Width</b>	139.7 mm   5.5 in
<b>Length</b>	266.7 mm   10.5 in
<b>Mounting Diameter 2, maximum</b>	88.9 mm   3.5 in
<b>Mounting Diameter 2, minimum</b>	60.96 mm   2.4 in
<b>Mounting Diameter, maximum</b>	88.9 mm   3.5 in
<b>Mounting Diameter, minimum</b>	60.96 mm   2.4 in

### Material Specifications

<b>Material Type</b>	Hot dip galvanized steel
----------------------	--------------------------

### Packaging and Weights

<b>Included</b>	Hardware   Plates
<b>Packaging quantity</b>	1
<b>Weight, net</b>	5 kg   11.023 lb

### Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value

# VZWSMART-MSK14 | UNIVERSAL ADJUSTABLE CROSSOVER

---

REACH-SVHC

Compliant as per SVHC revision on [www.andrew.com/ProductCompliance](http://www.andrew.com/ProductCompliance)

ROHS

Compliant

UK-ROHS

Compliant

