


MTC4107S

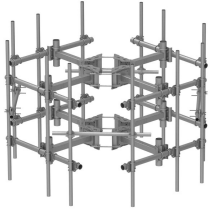

Four-Sector Double T-Arm Monopole Mount, Includes (2) Ring Mounts for 10"-30" OD Monopole, 6 ft x 3-1/2" OD face pipes, (12) 2-3/8" OD x 96" Antenna Pipes

Product Classification

Product Type Monopole T-frame kit

General Specifications

Mounting Monopole, 254–762 mm (10–30 in) OD

Pipe, quantity 12

Sectors, quantity 4

Dimensions

Height 2,438.4 mm | 96 in

Face Width 1.829 m | 6 ft

Width 1,828.8 mm | 72 in

Pipe Length 2,438.4 mm | 96 in

Face Support Pipe Diameter 88.9 mm | 3.5 in

Mounting Diameter, maximum 762 mm | 30 in

Mounting Diameter, minimum 254 mm | 10 in

Pipe Outer Diameter 60.325 mm | 2.375 in

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

Wind Rating For Specifications, please contact your local ANDREW representative

Wind Rating Test Method TIA/EIA-222-G

Packaging and Weights

Included Frame | Pipe mounts | Plain end pipes | Ring mounts (2)

Packaging quantity 1

MTC4107S

Weight, net 897.024 kg | 1,977.6 lb

* Footnotes

Wind Rating BWS—Base Wind Speed; FBC—Florida Building Code