


# URXMTMTGD

---

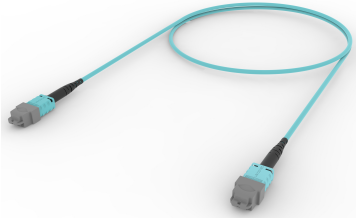

Ultra Low Loss (ULL) OM4 MPO12 (Pinned) Polarity and Gender Changeable, Fiber Extension Cable Assembly, 12-Fiber, Low Smoke Zero Halogen

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   Europe   Latin America   Middle East /Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber array cable assembly
<b>Product Brand</b>	SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

<b>Connector A, quantity</b>	1
<b>Color, boot A</b>	Black
<b>Color, connector A</b>	Aqua
<b>Connector B, quantity</b>	1
<b>Color, boot B</b>	Black
<b>Color, connector B</b>	Aqua
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Aqua
<b>Interface, Connector A</b>	MPO-12/UPC Male
<b>Interface Feature, connector A</b>	Gender changeable
<b>Interface, Connector B</b>	MPO-12/UPC Male
<b>Interface Feature, connector B</b>	Gender changeable
<b>Jacket Color</b>	Aqua
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Total Fibers, quantity</b>	12

## Dimensions


<b>Cable Assembly Length Range (m)</b>	1 – 305
--	---------

# URXMTMTGD

Cable Assembly Length Range (ft)

1 – 999

## Ordering Tree

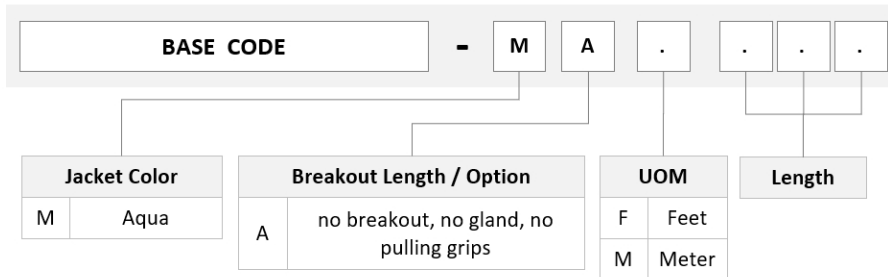

## Optical Specifications

**Fiber Mode** Multimode

**Fiber Type** OM4, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Indoor | Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

**Agency** **Classification**

ANATEL Compliant

