

# SEC3-B3C1G3BA000



NOVUX™ SEC Closure, splice/patch, 4x SC/APC adapter, 1x factory-installed 1:4 SC/APC Grade B pre-connectorized splitter, mounting included, black

- Design optimized for FTTH façade applications with gray and black colors
- Agnostic to connectivity technologies: splice, connector, field-installable connector for agility and flexibility
- Innovative removable hinge design allows cover to open from the left, right, or top
- Identification plate for either QR code or customer logo
- QR code and CommScope cTrak® app for one-click access to all product information

## Product Classification

<b>Regional Availability</b>	EMEA
<b>Regional Availability Note</b>	Contact your local CommScope representative for specific availability
<b>Product Type</b>	In-line, rectangular fiber closure
<b>Product Brand</b>	NOVUX™
<b>Product Series</b>	SEC100

## General Specifications

<b>Cable Capacity, Branch</b>	2 Round 8.0–12.0 mm (0.31–0.47 in)
<b>Cable Capacity, Drop</b>	6 Round 3.0–6.0 mm (0.12–0.23 in) for pre-connectorized cables   6 Round 3.0–7.0 mm (0.12–0.27 in)
<b>Cable Capacity, Feeder</b>	2 Round 8.0–12.0 mm (0.31–0.47 in)
<b>Cable Ports Quantity, total</b>	10 round ports
<b>Cable Sealing Type</b>	Gasket/grommet configuration
<b>Closure Sealing Type</b>	Hinged with lock
<b>Closure Style</b>	In-line
<b>Color</b>	Black
<b>Mounting</b>	Facade   Wall
<b>Network Area Type</b>	Drop
<b>Port Type</b>	SC/APC
<b>Port, quantity</b>	4
<b>Splice Tray Included, quantity</b>	1
<b>Splice Tray Type Included</b>	18-way, heat shrink

# SEC3-B3C1G3BA000


<b>Splices per Tray, quantity</b>	18
<b>Splicing Capacity, maximum</b>	4
<b>Splicing Capacity, Single Fusion, maximum</b>	4
<b>Splicing Type, Supported</b>	Single fusion
<b>Split Ratio</b>	Symmetrical
<b>Splitter Type</b>	1 x 4
<b>Splitter, quantity</b>	1

## Dimensions

<b>Height</b>	130 mm   5.118 in
<b>Width</b>	216 mm   8.504 in
<b>Depth</b>	62 mm   2.441 in

## Ordering Tree

### Ordering information

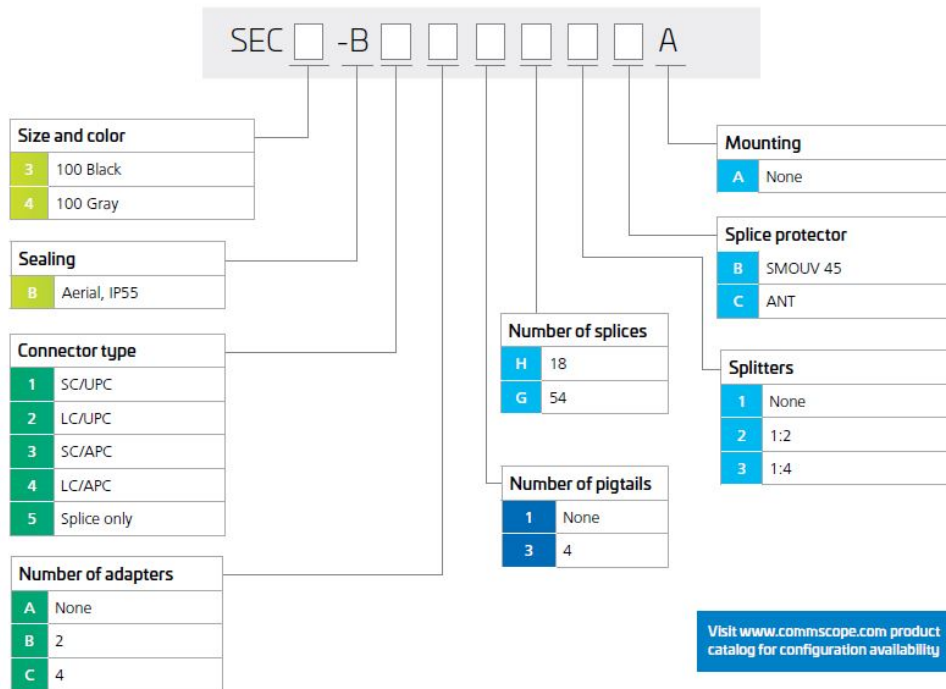

## Optical Specifications

<b>Fiber Type</b>	G.657.A1   G.657.A2   G.657.B3
-------------------	--------------------------------

# SEC3-B3C1G3BA000

---

## Environmental Specifications

<b>Environmental Space</b>	Facade   Outdoor
<b>Qualification Standards</b>	IP55
<b>UV Resistance</b>	UV stabilized

## Packaging and Weights

<b>Included</b>	1x factory-installed 1:4 SC/APC Grade B pre-connectorized splitter
<b>Packaging quantity</b>	1
<b>Packaging Type</b>	Box   Carton