


UKVQXQXTL

Base Product

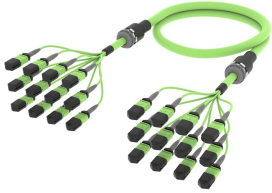

Ultra Low Loss (ULL) OM5 MPO8 UPC (pinned) to MPO8 UPC (pinned) Fiber Trunk Cable Assembly, 96-Fiber, Armored Indoor Dual Rated (OFNR /LSZH)

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	12
Color, boot A	Gray
Color, connector A	Lime green
Connector B, quantity	12
Color, boot B	Gray
Color, connector B	Lime green
Construction Type	Armored Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-08/UPC Male
Interface, Connector B	MPO-08/UPC Male
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	96

Dimensions

Breakout Length	22 in
------------------------	-------

UKVQXQXTL

Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree



Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0° 4.40 lb @ 90°
--	-------------------------------

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM5, LazrSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
EN50575 CPR Cable EuroClass Fire Performance	Dca
Environmental Space	Dual Rated LSZH/Riser Indoor

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

UKVQXQXTL



Included Products

- | | | |
|---------------------------------------|---|---|
| 760256040
N-096-MZ-5G-F08LM/20T/B2 | - | Fiber indoor cable, Riser/LSZH rated, MPO Trunk, interlocking aluminum armored, Multimode OM5, 96 fiber multi-unit with 8 fiber subunits, Gel-free, Feet jacket marking, Lime green jacket color, B2ca flame rating |
| 860659021 | - | MPO8, LL, MALE, OM5, LIME, 2MM |