


UKVRZUC8N

Base Product

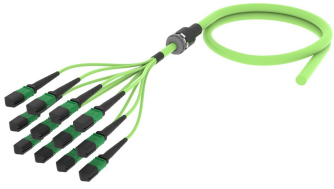

Ultra Low Loss (ULL) OM5 MPO16 APC (pinned) to Unconnectorized, Fiber Trunk Cable Assembly, 192-Fiber, Armored Indoor Dual Rated (OFNR/LSZH)

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	12
Color, boot A	Black
Color, connector A	Green
Connector B, quantity	0
Construction Type	Armored Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-16/APC Male
Interface, Connector B	Unterminated
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	16
Total Fibers, quantity	192

Dimensions


Breakout Length	22 in
Cable Assembly Length Range (m)	3 – 305

UKVRZUC8N

Cable Assembly Length Range (ft)

10 – 999

Ordering Tree

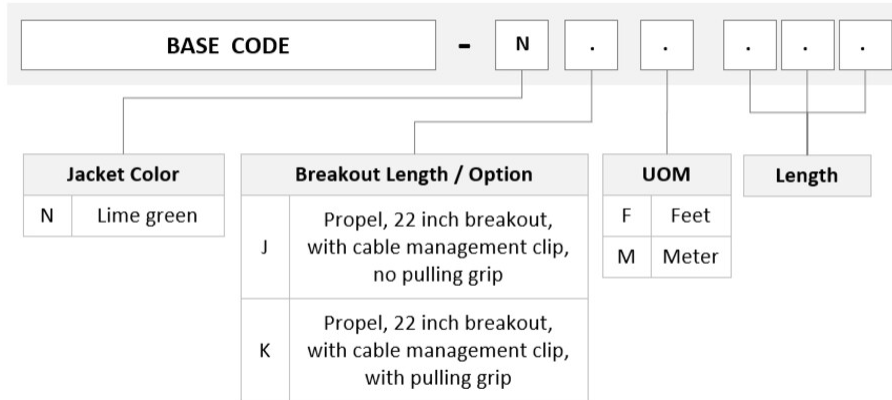

Mechanical Specifications

Cable Retention Strength, maximum

11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode

Multimode

Fiber Type

OM5, LazrSPEED®

Environmental Specifications

Operating Temperature

-10 °C to +60 °C (+14 °F to +140 °F)

EN50575 CPR Cable EuroClass Fire Performance

Dca

Environmental Space

Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Above maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted

UKVRZUC8N



Included Products

- 760256216
N-192-MZ-5G-F16LM/30T/B2
 - 860659158
- Fiber indoor cable, Riser/LSZH rated, MPO Trunk, interlocking aluminum armored, OM5 multimode, 192 fiber, Feet jacket marking, Lime green jacket color, B2ca flame rating
 - Fiber Optic Connector Kit, multimode, OM3/OM4, MPO-16/APC, ULL, pinned, green, for 3 mm cable