


UKXQXUCTL

Base Product

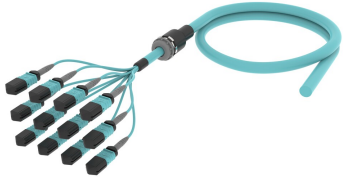

Ultra Low Loss (ULL) OM4 MPO8 UPC (pinned) to Unconnectorized Fiber Trunk Cable Assembly, 96-Fiber, Armored Indoor Dual Rated (OFNR /LSZH)

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	12
Color, boot A	Gray
Color, connector A	Aqua
Connector B, quantity	0
Construction Type	Armored Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-08/UPC Male
Interface, Connector B	Unterminated
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	96

Dimensions

Breakout Length	22 in
Cable Assembly Length Range (m)	3 – 305

UKXQXUCTL

Cable Assembly Length Range (ft)

10 – 999

Ordering Tree



Mechanical Specifications

Cable Retention Strength, maximum

11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode

Multimode

Fiber Type

OM4, LazrSPEED®

Environmental Specifications

Operating Temperature

-10 °C to +60 °C (+14 °F to +140 °F)

EN50575 CPR Cable EuroClass Fire Performance

Dca

Environmental Space

Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Above maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted

UKXQXUCTL



Included Products

- 760256021
N-096-MZ-5K-F08AQ/20T/B2 – Fiber indoor cable, LazrSPEED® Riser/LSZH rated, MPO Trunk, interlocking aluminum armored, Multimode OM4, 96 fiber multi-unit with 8 fiber subunits, Gel-free, Feet jacket marking, Aqua jacket color, B2ca flame rating
- 860659019 – MPO8, LL, MALE, OM3/4, AQUA, 2MM