


INSTALLATION INSTRUCTIONS

7/16 DIN Connectors Fitted to FSJ2-50 Cable.

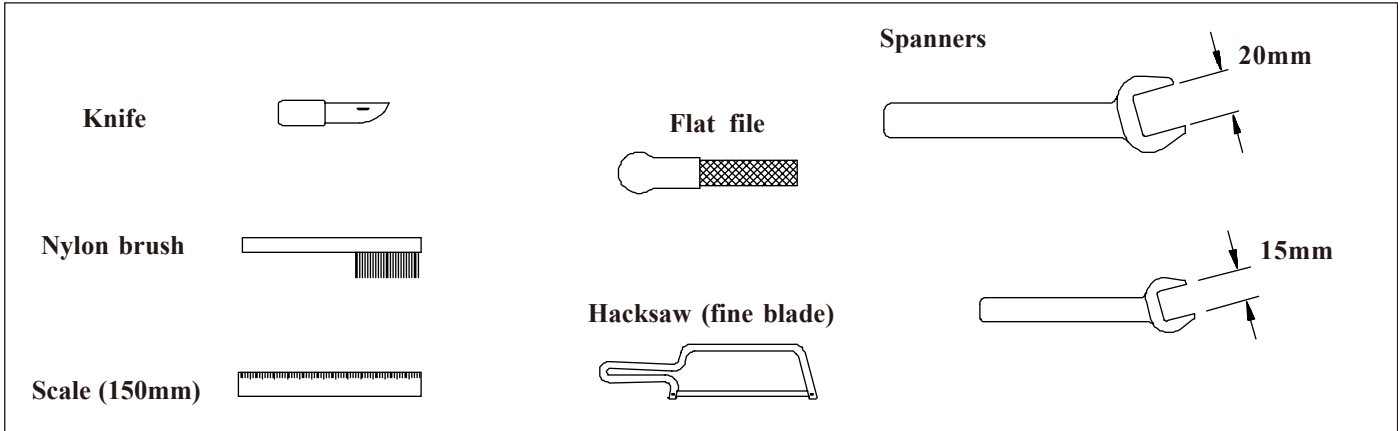

**READ THE INSTRUCTIONS THOROUGHLY
BEFORE ASSEMBLY**



1

Do not damage inner conductor
No dañar el conductor interno
Ne pas endommager le conducteur central
Innenleiter nicht beschädigen

Remove foam
Quitar la espuma
Retirer la mousse
Schaumkern entfernen

FSJ2-50

Or O Ou Oder

Andrew EASIAx® 241372

2

Do not damage inner conductor
No dañar el conductor interno
Ne pas endommager le conducteur central
Innenleiter nicht beschädigen

Remove adhesive
Raspar el adhesivo
Retirer l'adhésif
Klebstoff entfernen

22mm
[7/8]

45° x 1mm
[45° x 3/64]

6mm
[15/64]


3

Apply Sparingly
Aplicar Ligeramente
Appliquer un peu de Graisse au Silicone
Sparsam auftragen



Andrew


1.5mm
[1/16]

4

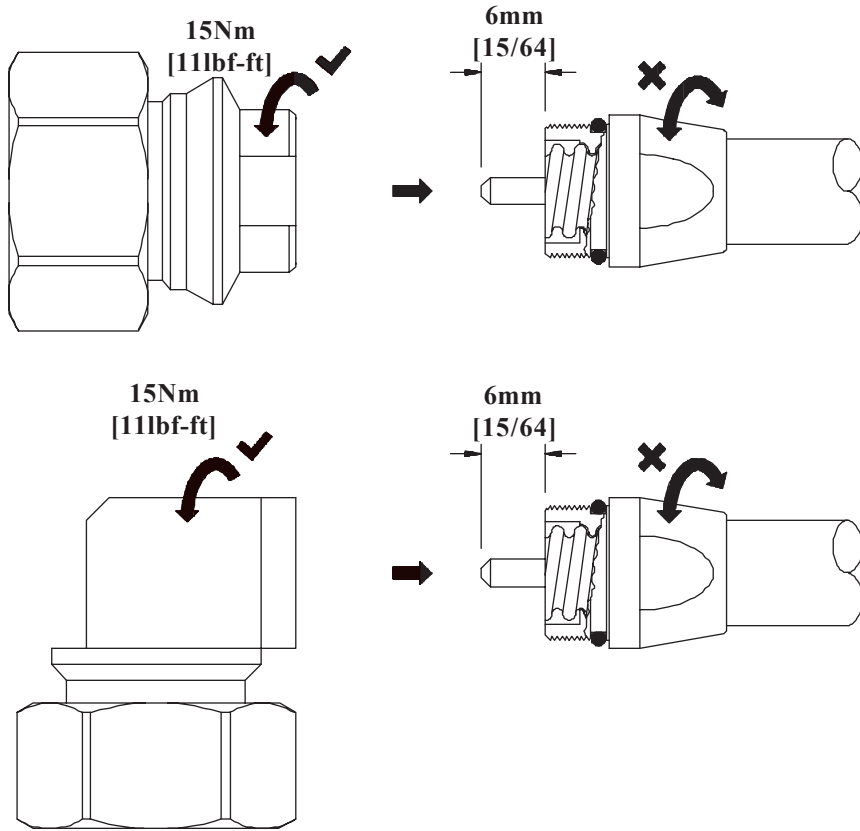

5

 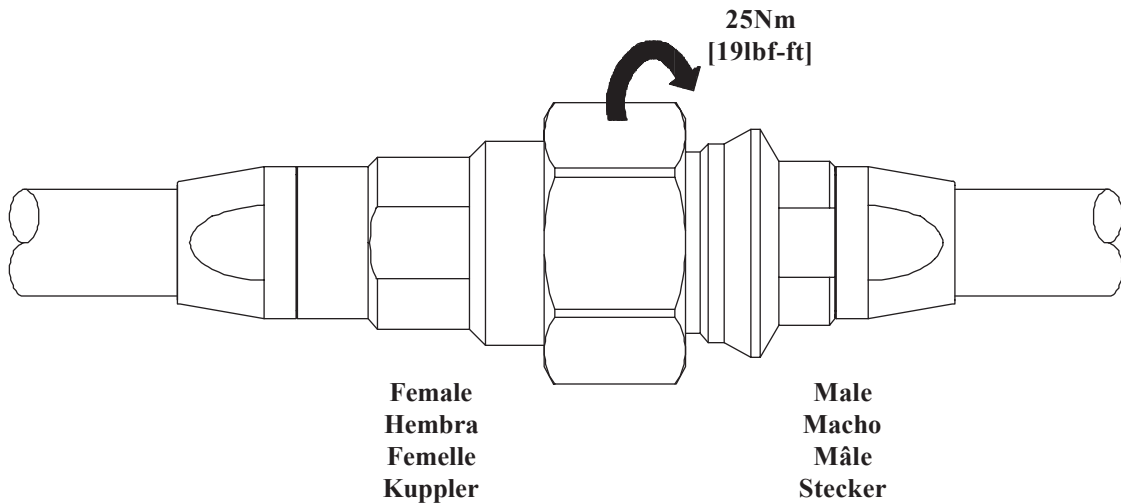

	表一 有毒有害物质或元素名称及含量标识格式					
	有毒有害物质或元素					
部件名称 (Part Name)	铅 (Pb)	汞 (Hg)	镉 (Cd)	六价铬 (Cr6+)	多溴联苯 (PBB)	多溴二苯醚 (PBDE)
连接器 (Connector)	X	O	O	O	O	O

O: 表示有毒有害物质在该部件所有的均质材料中的含量均在SJ/T 11363-2006规定的限量要求以下。
X: 表示该有毒有害物质至少在该部件的某一均质材料中的含量超出SJ/T 11363-2006规定的限量要求。



Notice: Andrew disclaims any liability or responsibility for the results of improper or unsafe installation, inspection, maintenance, or removal practices.

Andrew Corporation
3 Westbrook Corporate Center, Suite 900, Westchester, Illinois U.S.A. 60154
+1 (779) 435-8579 Fax (U.S.A.): 1-800-349-5444
www.andrew.com

Copyright © 2009 by Andrew Corporation

Customer Service, 24 hours
U.S.A., Canada, Mexico: 1-800-255-1479
U.K.: 0800 250055
Other Europe: +44 592 782 612
China: +86 512-6256-8805