


3-2105032-5

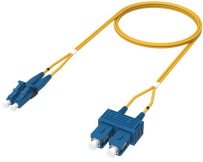

Fiber Optic Patch Cord, Duplex, Singlemode, LC/UPC to SC/UPC, yellow, 35 m

Product Classification

| | |
|------------------------------|--|
| Regional Availability | Asia Australia/New Zealand China Europe India Middle East/Africa |
| Portfolio | CommScope® |
| Product Type | Fiber patch cord, duplex |
| Product Series | 210 |

General Specifications


| | |
|-------------------------------|--------|
| Connector A, quantity | 2 |
| Color, boot A | Blue |
| Color, connector A | Blue |
| Connector B, quantity | 2 |
| Color, boot B | Blue |
| Color, connector B | Blue |
| Interface, Connector A | LC/UPC |
| Interface, Connector B | SC/UPC |
| Jacket Color | Yellow |
| Total Fibers, quantity | 2 |

Dimensions

| | |
|-----------------------------|-------------------|
| Cord Length | 35 m 114.829 ft |
| Diameter Over Jacket | 1.8 mm 0.071 in |

Ordering Tree

 3-2105032-5



| Examples of Lengths (meters) | |
|------------------------------|-----------------|
| -5 | 5 meters |
| 1- -0 | 10 meters |
| 1- -5 | 15 meters |
| 7- -5 | 75 meters |
| 8- -0 | 80 meters |
| 9- -y | Specific length |

Optical Specifications

Fiber Mode Singlemode

Fiber Type OS2

Environmental Specifications

Environmental Space Dual Rated LSZH/Riser

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

| Agency | Classification |
|------------|-----------------------------------|
| CHINA-ROHS | Above maximum concentration value |
| ROHS | Compliant/Exempted |
| UK-ROHS | Compliant/Exempted |

