


4-2105032-0

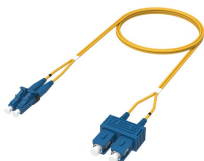

Fiber Optic Patch Cord, OS2, LC/SC duplex, 1.8 mm LSZH & OFNR, 40 m

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Middle East/Africa
Portfolio	CommScope®
Product Type	Fiber patch cord, duplex
Product Series	210

General Specifications


Connector A, quantity	2
Color, boot A	Blue
Color, connector A	Blue
Connector B, quantity	2
Color, boot B	Blue
Color, connector B	Blue
Interface, Connector A	LC/UPC
Interface, Connector B	SC/UPC
Jacket Color	Yellow
Polarity	Pairs, flipped
Total Fibers, quantity	2

Dimensions

Cord Length	40 m 131.234 ft
Diameter Over Jacket	1.8 mm 0.071 in

Ordering Tree

 4-2105032-0



Examples of Lengths (meters)	
-5	5 meters
1- -0	10 meters
1- -5	15 meters
7- -5	75 meters
8- -0	80 meters
9- -y	Specific length

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	OS2
Insertion Loss, maximum, connector A	0.3 dB
Insertion Loss, maximum, connector B	0.5 dB
Return Loss, minimum, connector A	50 dB
Return Loss, minimum, connector B	50 dB

Environmental Specifications

Environmental Space	Dual Rated LSZH/Riser
----------------------------	-----------------------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



4-2105032-0
