


# 2105084-1

---

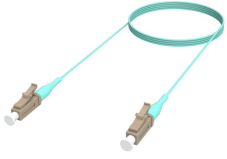

Fiber Optic Patch Cord, Simplex, 0.9mm, LSZH, Multimode OM4, LC/UPC to LC/UPC, Aqua, 1 m

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   China   India |
| <b>Portfolio</b>             | CommScope®                                   |
| <b>Product Type</b>          | Fiber patch cord, simplex                    |
| <b>Product Series</b>        | 210  |

## General Specifications


|                               |        |
|-------------------------------|--------|
| <b>Connector A, quantity</b>  | 1      |
| <b>Color, boot A</b>          | Aqua   |
| <b>Color, connector A</b>     | Beige  |
| <b>Connector B, quantity</b>  | 1      |
| <b>Color, boot B</b>          | Aqua   |
| <b>Color, connector B</b>     | Beige  |
| <b>Interface, Connector A</b> | LC/UPC |
| <b>Interface, Connector B</b> | LC/UPC |
| <b>Jacket Color</b>           | Aqua   |
| <b>Total Fibers, quantity</b> | 1      |

## Dimensions

|                             |                   |
|-----------------------------|-------------------|
| <b>Cord Length</b>          | 1 m   3.281 ft    |
| <b>Diameter Over Jacket</b> | 0.9 mm   0.035 in |

## Ordering Tree

# 2105084-1

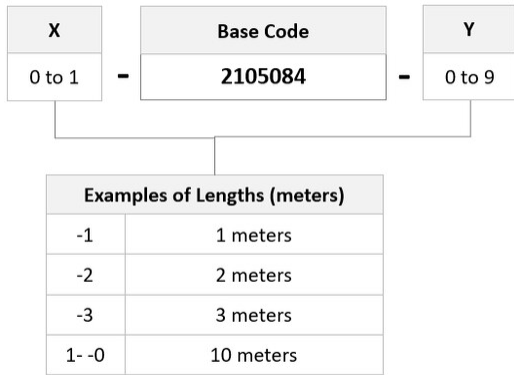

## Mechanical Specifications

**Cable Retention Strength, maximum** 1.00 lb @ 0° | 1.00 lb @ 90°

## Optical Specifications

**Fiber Mode** Multimode  
**Fiber Type** OM4, LazrSPEED®  
**Insertion Loss, maximum** 0.3 dB  
**Return Loss, minimum** 27 dB

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)  
**Environmental Space** Low Smoke Zero Halogen (LSZH)

## Packaging and Weights

**Packaging quantity** 1

## Regulatory Compliance/Certifications

| Agency     | Classification  |
|------------|---|
| CHINA-ROHS | Below maximum concentration value   |
| REACH-SVHC | Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS       | Compliant   |
| UK-ROHS    | Compliant   |



