


# 2105086-2

---

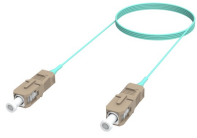

Fiber Optic Patch Cord, Simplex, 0.9mm, LSZH, Multimode OM4, SC/UPC to SC/UPC, Aqua, 2 m

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   China   India
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber patch cord, simplex
<b>Product Series</b>	210

## General Specifications

 
<b>Connector A, quantity</b>	1
<b>Color, boot A</b>	Aqua
<b>Color, connector A</b>	Beige
<b>Connector B, quantity</b>	1
<b>Color, boot B</b>	Aqua
<b>Color, connector B</b>	Beige
<b>Interface, Connector A</b>	SC/UPC
<b>Interface, Connector B</b>	SC/UPC
<b>Jacket Color</b>	Aqua
<b>Total Fibers, quantity</b>	1

## Dimensions

<b>Cord Length</b>	2 m   6.562 ft
<b>Diameter Over Jacket</b>	0.9 mm   0.035 in

## Ordering Tree

# 2105086-2



Examples of Lengths (meters)	
-1	1 meters
-2	2 meters
-3	3 meters
1- -0	10 meters

## Mechanical Specifications

**Cable Retention Strength, maximum** 1.00 lb @ 0° | 1.00 lb @ 90°

## Optical Specifications

**Fiber Mode** Multimode  
**Fiber Type** OM4, LazrSPEED®  
**Insertion Loss, maximum** 0.3 dB  
**Return Loss, minimum** 27 dB

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)  
**Environmental Space** Low Smoke Zero Halogen (LSZH)

## Packaging and Weights

**Packaging quantity** 1

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant



