


FGS-MHRT-M/F

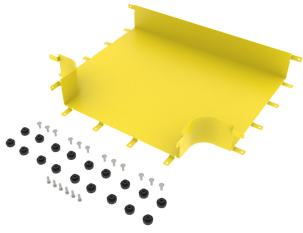

FiberGuide® Horizontal T, 4x18in, 4x12in Exit, Yellow

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Tee
Product Brand	FiberGuide®
Product Series	FGS

General Specifications

Product Feature	Transition
Color	Yellow
Orientation	Horizontal
Section Type	Tee section

Dimensions

Height	114 mm 4.488 in
Width	476 mm 18.74 in
Length	601 mm 23.661 in
System Dimensions	102 mm x 305 mm (4 in x 12 in) 102 mm x 457 mm (4 in x 18 in)

Ordering Tree

FGS-MHRT-M/F

9 10
 FGS B - MHRT - H

Section Color

9	empty	yellow
	B	black

Section Size

10	A	4 x 4 in
	B	4 x 6 in
	B-VS	4 x 6 in, variable support bracket
	F	4 x 12 in
	F/B	4 x 12 in, 6 in exit
	F/B-S	4 x 12 in, 6 in exit, with variable support bracket
	F/B-VS	4 x 12 in, 6 in exit, variable support bracket
	F-VS	4 x 12 in, variable support bracket
	G	2 x 6 in
	H	4 x 24 in
	H/F	4 x 24 in, 12 in exit
	H/F-VS	4 x 24 in, 12 in exit, variable support bracket
	M	4 x 18 in
	M/F	4 x 18 in, 12 in exit
	M/H	4 x 18 in, 24 in exit
	H/M	4 x 18 in

* Support brackets only come in black

Material Specifications

Material Type Steel

Environmental Specifications

Safety Standard CSA | UL

Packaging and Weights

Weight, net 2.85 kg | 6.283 lb

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

REACH-SVHC

ROHS

UK-ROHS

Classification

Below maximum concentration value

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant

Compliant

